


## EMT Rain Tight Compression Connectors with Insulated Throat

Rain tight. Concrete tight. Steel. Blue compression nuts help identify these products as rain tight.

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
820ART	82045	1/2	1/2	50	50	1.670	.500	1.125
821ART	82046	3/4	3/4	50	50	1.719	.500	1.375
822ART	82047	1	1	25	25	1.885	.563	1.688
823ART	82048	1-1/4	1-1/4	10	10	2.166	.688	2.063
824ART	82049	1-1/2	1-1/2	10	10	2.253	.688	2.250
825ART	82050	2	2	10	10	2.360	.750	2.750
826ART	83000	2-1/2	2-1/2	12	12	3.610	.813	3.625
827ART	83001	3	3	12	12	3.690	.938	4.250
828ART	83002	3-1/2	3-1/2	6	6	3.896	1.000	4.688
829ART	83003	4	4	6	6	4.197	1.000	5.188

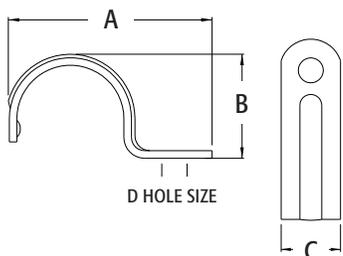


## Extra Duty 1-Hole EMT Straps

Plated steel, click on.

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	EMT SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D
370	00370	1/2	100	1000	1.696	.770	.570	.250 x .320 slot
371	00371	3/4	100	1000	1.955	.984	.640	.250 x .320 slot
372	00372	1	50	500	2.321	1.186	.760	.320
373	00373	1-1/4	25	250	2.886	1.540	.880	.380
374	00374	1-1/2	25	100	3.223	1.790	1.000	.380
375	00375	2	25	100	3.992	2.225	1.130	.440
346	00346	2-1/2	25	25	4.930	2.900	1.250	.560
347	00347	3	25	25	5.560	3.440	1.250	.560
348	00348	3-1/2	10	10	6.400	3.950	1.250	.560
349	00349	4	10	10	6.810	4.440	1.250	.560

MADE IN USA.

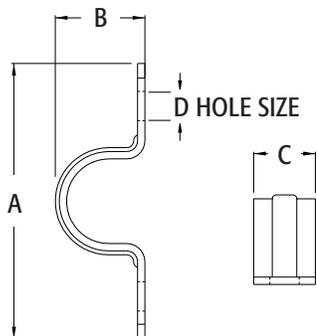

## 2-Hole EMT Straps

Plated steel, click on.

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	EMT SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D
360	00360	1/2	100	1000	2.200	.790	.560	.187
361	00361	3/4	50	500	2.700	.980	.620	.187
362	00362	1	50	250	2.975	1.185	.690	.187
363	00363	1-1/4	50	250	3.650	1.535	.720	.250
364	00364	1-1/2	25	250	4.250	1.765	.830	.250
365	00365	2	25	250	4.775	2.300	1.000	.386
356	00356	2-1/2	25	100	5.980	2.855	1.000	.374
357	00357	3	25	25	6.664	3.559	1.000	.374
358	00358	3-1/2	10	10	7.436	4.030	1.000	.374
359	00359	4	10	10	7.982	4.647	1.000	.429

MADE IN USA.