

Duplex Connector

Zinc die-cast. Single screw for Flex • AC • MCI • MCI-A • NM cable.



CATALOG NUMBER	UPC/DCI/NAE MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D	CABLE RANGE
846	00846	3/8	1/2	25	250	1.542	.437	.888	1.672	.150-.612


Refer to chart on page E-22 for a list of cable types.

Refer to chart on page E-25 for MCI-A cable ranges.

Concrete tight when taped.



E60812 LR49636

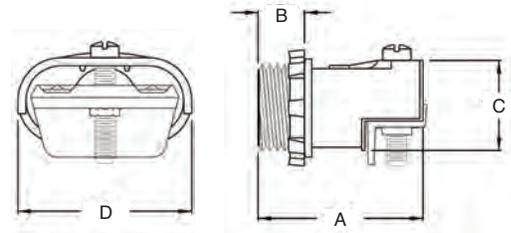

Duplex SNAP-TITE® Connectors

Zinc die-cast. Single screw for Flex • AC • MCI • MCI-A • NM cable.



CATALOG NUMBER	UPC/DCI/NAE MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D	CABLE RANGE
846ST‡	80050	3/8	1/2	25	250	1.635	.510	.888	1.654	.150-.612
846AST*	80052	3/8	1/2	25	250	1.728	.603	.888	1.654	.150-.612

*Provided with insulated throat.

‡Also for MCI-A cable.

Refer to page E-27 for cable ranges.


Refer to chart on page E-24 for a list of cable types.

SNAP-TITE® products have been tested and listed by UL in accordance with UL's ground fault requirements. For additional information see page 6.

Concrete tight when taped.



E60812 LR49636

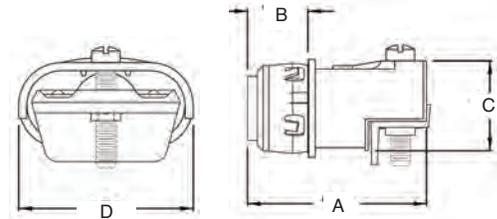

Duplex Connector

Twin screw with steel strap. Zinc die-cast. For Flex • NM • AC • MCI steel and aluminum jacketed cables.



CATALOG NUMBER	UPC/DCI/NAE MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D	CABLE RANGE
846SS	80054	3/8	1/2	25	250	1.562	.437	.888	2.200	.210-.612

Refer to chart on page E-22 for a list of cable types.

Concrete tight when taped.



E60812 LR49636

