



## 90° Duplex Connector

Zinc die-cast. Twin screw for Flex • NM • AC • MCI steel and aluminum jacketed cables • MCI-A cable.




CATALOG NUMBER	UPC/DCI/NAE MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D	CABLE RANGE
84690	00090	3/8	1/2	10	100	1.087	1.707	1.965	.379	.512-.612

Refer to chart on page E-22 for a list of cable types.  
Refer to chart on page E-25 for MCI-A cable ranges.  
Concrete tight when taped.



E60812 LR49636

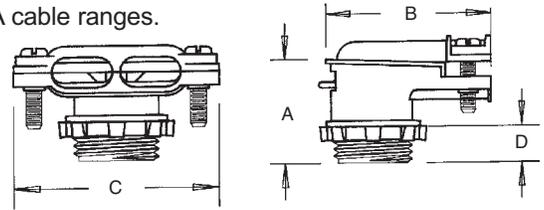

## 90° Duplex SNAP-TITE® Connector

Zinc die-cast. Twin screw for NM • Flex • AC • MCI steel and aluminum jacketed cables • MCI-A cable.




CATALOG NUMBER	UPC/DCI/NAE MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D	CABLE RANGE
846ST	58230	3/8	1/2	10	100	1.087	1.707	1.965	.458	.512-.612

Refer to chart on page E-22 for a list of cable types.  
Refer to chart on page E-25 for MCI-A cable ranges.  
SNAP-TITE® products have been tested and listed by UL in accordance with UL's ground fault requirements. For additional information see page 6.  
Concrete tight when taped.



E20643 LR49636

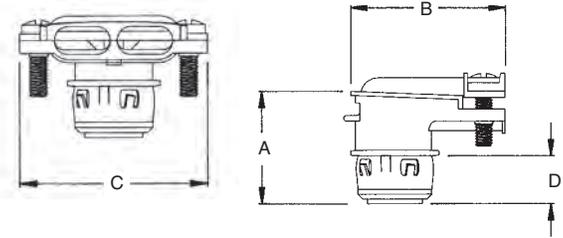

## Set-Screw Connectors

For Flex • AC • MCI cable.  
Zinc die-cast. Not for use with aluminum jacketed cables.




CATALOG NUMBER	UPC/DCI/NAE MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	CABLE RANGE	END STOP DIAMETER
L48	34800	1/2	1/2	25	250	1.470	.450	1.260	.625-.915	.620
L49	34900	3/4	3/4	20	200	1.540	.450	1.500	.820-.910	.815

Refer to chart on page E-23 for a list of cable types.  
Concrete tight when taped.



E60812 LR49636

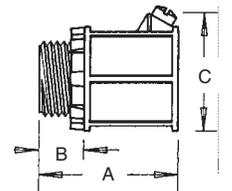

Flex • AC • MC