
 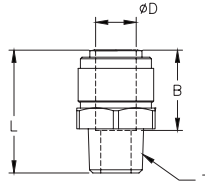




# HydroMode™ Potable Water Push-to-Connect Fittings

HydroMode push-to-connect male straight fitting with acetel body and synthetic rubber o-ring. For use with polyethylene and other flexible tubing. Five fittings per package.



| HydroMode™ Male Straight                                           |         |                    |           |          |      |      |            |      |                      |               |
|--------------------------------------------------------------------|---------|--------------------|-----------|----------|------|------|------------|------|----------------------|---------------|
| Inch Sizes - dimensions in millimeters (mm) unless otherwise noted |         |                    |           |          |      |      |            |      |                      |               |
| Part No.                                                           | Price   | Size (inch)        | ØD (inch) | T (NPTF) | B    | ØE   | H (inch)   | L    | Package Weight (lbs) | Qty. per pack |
| <a href="#">MS532-18N-P</a>                                        | \$4.75  | 5/32 in. x 1/8 NPT | 5/32      | 1/8      | 14.7 | 17.8 | 15.8 (5/8) | 22.2 | 0.1                  | 5             |
| <a href="#">MS532-14N-P</a>                                        | \$5.75  | 5/32 in. x 1/4 NPT | 5/32      | 1/4      | 14.7 | 17.8 | 15.8 (5/8) | 25.3 | 0.1                  | 5             |
| <a href="#">MS14-18N-P</a>                                         | \$5.75  | 1/4 in. x 1/8 NPT  | 1/4       | 1/8      | 16.9 | 17.8 | 15.8 (5/8) | 27.0 | 0.1                  | 5             |
| <a href="#">MS14-14N-P</a>                                         | \$6.00  | 1/4 in. x 1/4 NPT  | 1/4       | 1/4      | 16.9 | 17.8 | 15.8 (5/8) | 27.0 | 0.1                  | 5             |
| <a href="#">MS14-38N-P</a>                                         | \$8.25  | 1/4 in. x 3/8 NPT  | 1/4       | 1/4      | 16.9 | 21.4 | 19.0 (3/4) | 26.1 | 0.1                  | 5             |
| <a href="#">MS516-18N-P</a>                                        | \$6.00  | 5/16 in. x 1/8 NPT | 5/16      | 5/16     | 17.5 | 21.4 | 19.0 (3/4) | 28.4 | 0.1                  | 5             |
| <a href="#">MS516-14N-P</a>                                        | \$6.25  | 5/16 in. x 1/4 NPT | 5/16      | 5/16     | 17.5 | 21.4 | 19.0 (3/4) | 27.9 | 0.1                  | 5             |
| <a href="#">MS516-38N-P</a>                                        | \$9.50  | 5/16 in. x 3/8 NPT | 5/16      | 5/16     | 17.5 | 21.4 | 19.0 (3/4) | 26.5 | 0.1                  | 5             |
| <a href="#">MS516-12N-P</a>                                        | \$5.75  | 5/16 in. x 1/2 NPT | 5/16      | 5/16     | 17.5 | 25.0 | 22.2 (7/8) | 33.5 | 0.1                  | 5             |
| <a href="#">MS38-18N-P</a>                                         | \$12.00 | 3/8 in. x 1/8 NPT  | 3/8       | 3/8      | 20.2 | 23.0 | 20.6 (3/4) | 30.4 | 0.1                  | 5             |
| <a href="#">MS38-14N-P</a>                                         | \$9.50  | 3/8 in. x 1/4 NPT  | 3/8       | 3/8      | 20.2 | 23.0 | 20.6 (3/4) | 34.3 | 0.1                  | 5             |
| <a href="#">MS38-38N-P</a>                                         | \$11.00 | 3/8 in. x 3/8 NPT  | 3/8       | 3/8      | 20.2 | 23.0 | 20.6 (3/4) | 29.6 | 0.1                  | 5             |
| <a href="#">MS38-12N-P</a>                                         | \$16.00 | 3/8 in. x 1/2 NPT  | 3/8       | 1/2      | 20.2 | 25.0 | 22.2 (7/8) | 33.9 | 0.1                  | 5             |
| <a href="#">MS12-38N-P</a>                                         | \$14.50 | 1/2 in. x 3/8 NPT  | 1/2       | 3/8      | 25.1 | 27.4 | 25.4 (1.0) | 38.4 | 0.1                  | 5             |
| <a href="#">MS12-12N-P</a>                                         | \$15.00 | 1/2 in. x 1/2 NPT  | 1/2       | 1/2      | 25.1 | 27.4 | 25.4 (1.0) | 37.9 | 0.1                  | 5             |

HydroMode push-to-connect female straight fitting with acetel body and synthetic rubber o-ring. For use with polyethylene and other flexible tubing. Five fittings per package.

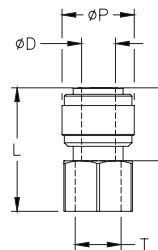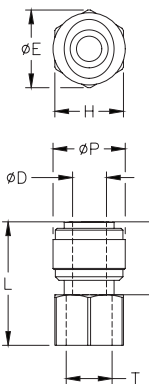

| HydroMode™ Female Straight                                         |        |                   |           |      |          |      |      |         |      |                      |               |
|--------------------------------------------------------------------|--------|-------------------|-----------|------|----------|------|------|---------|------|----------------------|---------------|
| Inch Sizes - dimensions in millimeters (mm) unless otherwise noted |        |                   |           |      |          |      |      |         |      |                      |               |
| Part No.                                                           | Price  | Size (inch)       | ØD (inch) | ØP   | T (NPTF) | B    | ØE   | H (Hex) | L    | Package Weight (lbs) | Qty. per pack |
| <a href="#">FS14-18N-P</a>                                         | \$9.00 | 1/4 in. x 1/8 NPT | 1/4       | 15.5 | 1/8      | 16.9 | 19.0 | 17.0    | 30.9 | 0.1                  | 5             |
| <a href="#">FS14-14N-P</a>                                         | \$9.00 | 1/4 in. x 1/4 NPT | 1/4       | 15.5 | 1/4      | 16.9 | 21.5 | 19.0    | 30.9 | 0.1                  | 5             |
| <a href="#">FS38-14N-P</a>                                         | \$9.75 | 3/8 in. x 1/4 NPT | 3/8       | 20.0 | 1/4      | 20.2 | 21.5 | 19.0    | 34.2 | 0.1                  | 5             |

# HydroMode™ Potable Water Push-to-Connect Fittings

HydroMode push-to-connect fittings are designed to work with potable water and beverages. Installing or removing flexible tubing is quick and easy. All fittings are made of NSF approved materials with NSF-51® and NSF-61® certifications. The body and collet of the fittings are made from polyoxymethylene (POM) also known as acetal, while the o-rings are made from ethylene propylene diene monomer (EPDM) which is a type of synthetic rubber.

## Features

- Designed for potable water and beverages
- NSF-51 and NSF-61 certified
- Easy tubing installation and removal
- Optional retaining clips prevent accidental tube removal
- Fittings rated for up to 145psi at 70°C (158°F)



*Push-to-Connect Fitting  
Cut-away Diagram*