




# Potable Water Push-to-Connect Fittings

HydroMode push-to-connect union reducing elbow fitting with acetel body and synthetic rubber o-ring. For use with polyethylene and other flexible tubing. Five fittings per package.

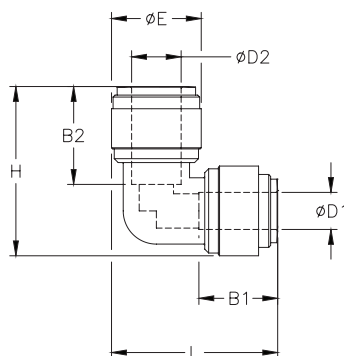


## HydroMode™ Union Reducing Elbow

*Inch Sizes - dimensions in millimeters (mm) unless otherwise noted*

| Part No.                    | Price   | Size (inch)        | ØD1 (inch) | ØD2 (inch) | B1   | B2   | ØE   | L    | H    | Package Weight (lbs) | Qty. per pack |
|-----------------------------|---------|--------------------|------------|------------|------|------|------|------|------|----------------------|---------------|
| <a href="#">URL516-14-P</a> | \$10.00 | 5/16 in. x 1/4 in. | 5/16       | 1/4        | 17.5 | 16.9 | 17.6 | 30.7 | 30.3 | 0.1                  | 5             |
| <a href="#">URL12-38-P</a>  | \$14.50 | 1/2 in. x 3/8 in.  | 1/2        | 3/8        | 25.1 | 20.2 | 23.0 | 43.4 | 42.6 | 0.2                  | 5             |

HydroMode push-to-connect union tee fitting with acetel body and synthetic rubber o-ring. For use with polyethylene and other flexible tubing. Five fittings per package.

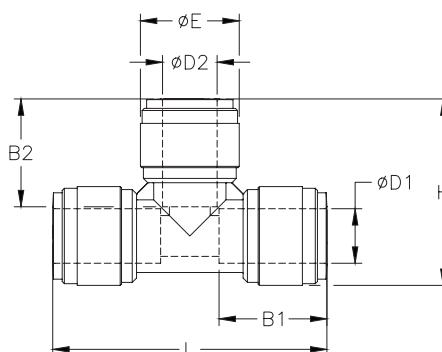

## HydroMode™ Union Tee

*Inch Sizes - dimensions in millimeters (mm) unless otherwise noted*


| Part No.                | Price   | Size (inch) | ØD1 (inch) | ØD2 (inch) | B1   | B2   | ØE   | H    | L    | Package Weight (lbs) | Qty. per pack |
|-------------------------|---------|-------------|------------|------------|------|------|------|------|------|----------------------|---------------|
| <a href="#">UT532-P</a> | \$11.00 | 5/32 in.    | 5/32       | 5/32       | 14.7 | 14.7 | 13.2 | 24.5 | 35.8 | 0.1                  | 5             |
| <a href="#">UT14-P</a>  | \$11.50 | 1/4 in.     | 1/4        | 1/4        | 16.9 | 16.9 | 15.5 | 28.8 | 42.0 | 0.1                  | 5             |
| <a href="#">UT516-P</a> | \$12.00 | 5/16 in.    | 5/16       | 5/16       | 17.5 | 17.5 | 17.6 | 30.7 | 43.8 | 0.1                  | 5             |
| <a href="#">UT38-P</a>  | \$14.50 | 3/8 in.     | 3/8        | 3/8        | 20.2 | 20.2 | 20.0 | 35.9 | 51.8 | 0.2                  | 5             |
| <a href="#">UT12-P</a>  | \$19.00 | 1/2 in.     | 1/2        | 1/2        | 25.1 | 25.1 | 23.0 | 43.4 | 63.8 | 0.2                  | 5             |

# HydroMode™ Potable Water Push-to-Connect Fittings

HydroMode push-to-connect fittings are designed to work with potable water and beverages. Installing or removing flexible tubing is quick and easy. All fittings are made of NSF approved materials with NSF-51® and NSF-61® certifications. The body and collet of the fittings are made from polyoxymethylene (POM) also known as acetal, while the o-rings are made from ethylene propylene diene monomer (EPDM) which is a type of synthetic rubber.

## Features

- Designed for potable water and beverages
- NSF-51 and NSF-61 certified
- Easy tubing installation and removal
- Optional retaining clips prevent accidental tube removal
- Fittings rated for up to 145psi at 70°C (158°F)

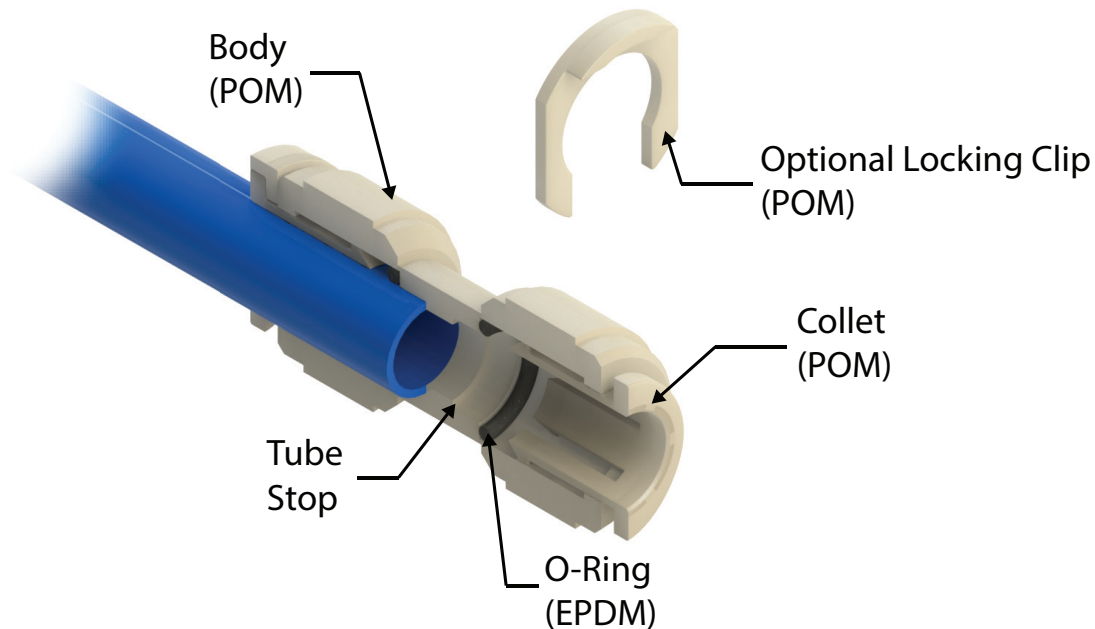

*Push-to-Connect Fitting  
Cut-away Diagram*