


Style AA Tweezers

For general assembly, very strong and precise tips with fine finish. Available in different materials and quality grades. Length: 5" (130mm)

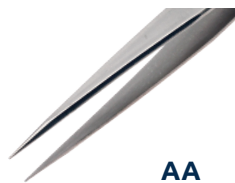

AA

Product ID	Description	Material
18013USA	Technik Tweezers AA-SA	Stainless Steel
18011-CS	Aven Tweezers AA-CS	Carbon Steel, Nickel/Chrome Plated
18013TS	Accu-Tek AA (Swiss Made)	Titanium
18013TT	Aven Tweezers AA	Titanium
18013EZ	E-Z Pik Tweezers AA Yellow	Stainless Steel
18013ARS	Artis Tweezers AA-SA	Stainless Steel

Style AC Tweezers

Sturdy tips for bending and handling very fine wire and components. Tweezers feature finger grips. Available in different materials and quality grades. Length: 4-3/4" (120mm)




AC

Product ID	Description	Material
18016USA	Technik Tweezers AC-SA	Stainless Steel
18014-CS	Aven Tweezers AC-CS	Carbon Steel, Nickel/Chrome Plated

Style MM Tweezers

General purpose, tweezers with hardened, precision tips and fine finish. Available in different materials and quality grades. Length: 5" (130mm)

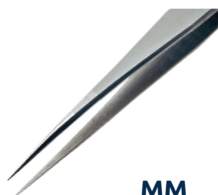

MM

Product ID	Description	Material
18023USA	Technik Tweezers MM-SA	Stainless Steel
18014-CS	Aven Tweezers MM-CS	Carbon Steel, Nickel/Chrome Plated
18023ARS	Artis Tweezers MM-SA	Stainless Steel

Style 00 Tweezers

Flat edges, heavy duty strong blades tapering to a regular strong point. Available in different materials and quality grades. Length: 4-3/4" (120mm)




00

Product ID	Description	Material
18032ACU	Accu-Tek Tweezers 00-SA	Stainless Steel
18032USA	Technik Tweezers 00-SA	Stainless Steel
18032-CS	Aven Tweezers 00-CS	Carbon Steel, Nickel/Chrome Plated
18032TS	Accu-Tek 00 (Swiss Made)	Titanium
18032TT	Aven Tweezers 00	Titanium
18032EZ	E-Z Pik Tweezers 00 Red	Stainless Steel
18032-ER	Comfort Grip Tweezers 00-SA	Stainless Steel
18032ARS	Artis Tweezers 00-SA	Stainless Steel

Style 00C Tweezers

Flat edges, heavy duty strong blades tapering to a regular strong point. Slightly shorter than 00. Length: 4-1/2" (115mm)

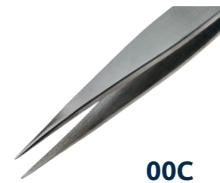

00C

Product ID	Description	Material
18034USA	Technik Tweezers 00C-SA	Stainless Steel

Style 00D Tweezers

Flat edges, heavy duty strong blades tapering to a regular strong point. Tweezers feature finger grips. Available in different materials and quality grades. Length: 4-3/4" (120mm)




00D

Product ID	Description	Material
18037ACU	Accu-Tek Tweezers 00D-SA	Stainless Steel
18037-MS	Mini 00D-SA (Swiss Made)	Stainless Steel
18037USA	Technik Tweezers 00D-SA	Stainless Steel
18036-CS	Aven Tweezers 00D-CS	Carbon Steel, Nickel/Chrome Plated
18037TT	Aven Titanium Tweezers 00D	Titanium

Style 0 Tweezers

Extremely fine straight points for general handling and positioning of miniature parts or fine wire. Available in different quality grades. Length: 4-3/4" (120mm)

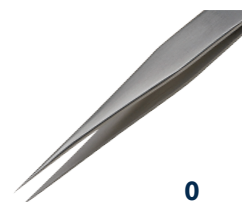


0

Product ID	Description	Material
18026ACU	Accu-Tek Tweezers 0-SA	Stainless Steel
18026USA	Technik Tweezers 0-SA	Stainless Steel

Style 0A Tweezers

Straight point tweezers with radius edges are uniquely designed for working in small yet dense areas. Length: 4-3/4" (120mm)

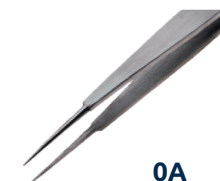


0A

Product ID	Description	Material
18027USA	Technik Tweezers 0A-SA	Stainless Steel

Style 0C Tweezers

Straight point tweezers with flat edges, fine tips and shortened overall length for delicate handling of small parts. Available in different quality grades. Length: 3-1/2" (90mm)

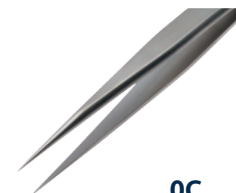

0C

Product ID	Description	Material
18029ACU	Accu-Tek Tweezers 0C-SA	Stainless Steel
18029USA	Technik Tweezers 0C-SA	Stainless Steel