



Customer information packet

CDP3310

.25HP, 1750RPM, DC, 56C, 3320P, TENV, F1

Specifications

Armature Voltage	90 V
Base Speed	1750 rpm
Enclosure	TENV
Frame	56C
Frame Material	Steel
Output Power	0.250 HP
Agency Approvals	CE
	CSA
	UR
Ambient Temperature	40 °C
Armature Current	2.5 a
Armature Inertia	7.804 lb-ft ²
Base Indicator	Rigid
Bearing Grease Type	Polyrex EM (-20F +300F)
Drip Cover	No Drip Cover
Duty Rating	CONT
Feedback Device	NO FEEDBACK
Heater Indicator	No Heater
Lifting Lugs	No Lifting Lugs
Motor Lead Exit	Ko Box
Motor Lead Quantity/Wire Size	2 @ 18 AWG, A
Motor Lead Termination	Flying Leads
Motor Standards	NEMA
Mounting Arrangement	F1
Overall Length	12.25 IN
Product Family	General Purpose
Pulley End Bearing Type	Sealed Bearing
RoHS Status	ROHS COMPLIANT
Service Factor	1.00
Shaft Diameter	0.625 IN
Shaft Extension Location	Pulley End
Shaft Ground Indicator	No Shaft Grounding

Part detail

Revision	AH
Type	DC
Mech. spec.	33-2024
Base	
Status	PRD/A
Elec. spec.	33WGZ118
Layout	33LY2024
Eff. date	10-24-2024
CD Diagram	CD0194
Poles	00
Leads	2#18 A 4.5"(+/-5") LG Y
Proprietary	False
Created date	01-01-0001


Shaft Rotation	Reversible
Shaft Slinger Indicator	No Slinger

Nameplate


NP0891L				
CAT.NO.	CDP3310			
SPEC.	33-2024Z118			
HP	.25/KW.18	ENCL	TENV	
RPM	1750 1/MIN IC410			
FRAME	56C	TYPE	3320P	
ARM V	90	ARM A	2.5	
FLD V		FLD A		
INSUL	F	AMB.	40	
DUTY	S1 CONT	SUPPLY	1.3	
BRG/DE	6203	BRG/ODE	6203	
BRUSHES	2/BP5011T01			
		BLANK	IP44 KG11	
SER.				
BLANK				
APRV-CE	Y	APRV-CSA	Y	APRV-UL Y

Accessories

Part number	Description	Multiplier
TK3300	TACHO MOUNTING KIT TK3300	A8
TK3300-HPU	HPU10 MOUNTING KIT 33P/34P TENV	

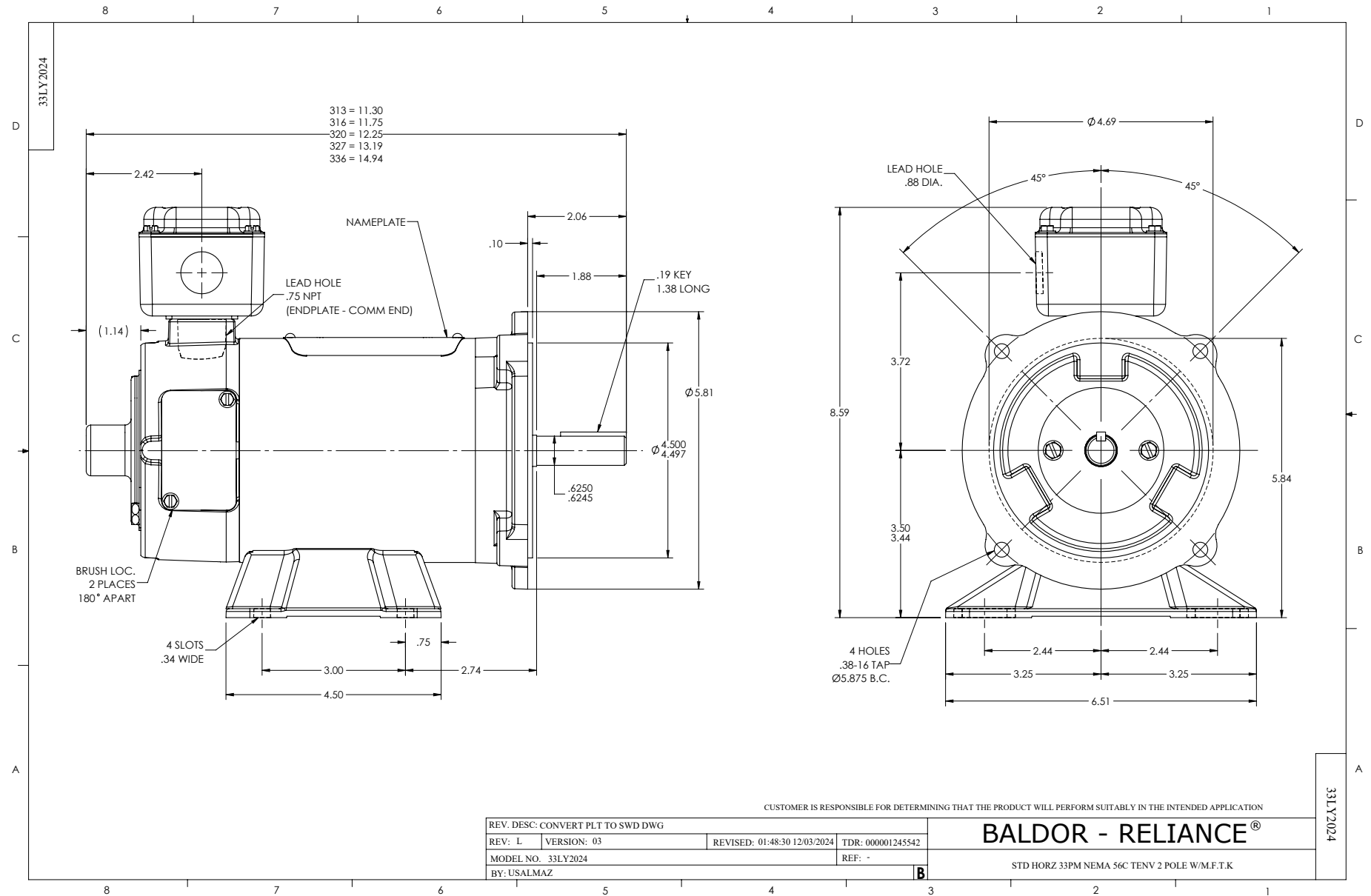

CD0194

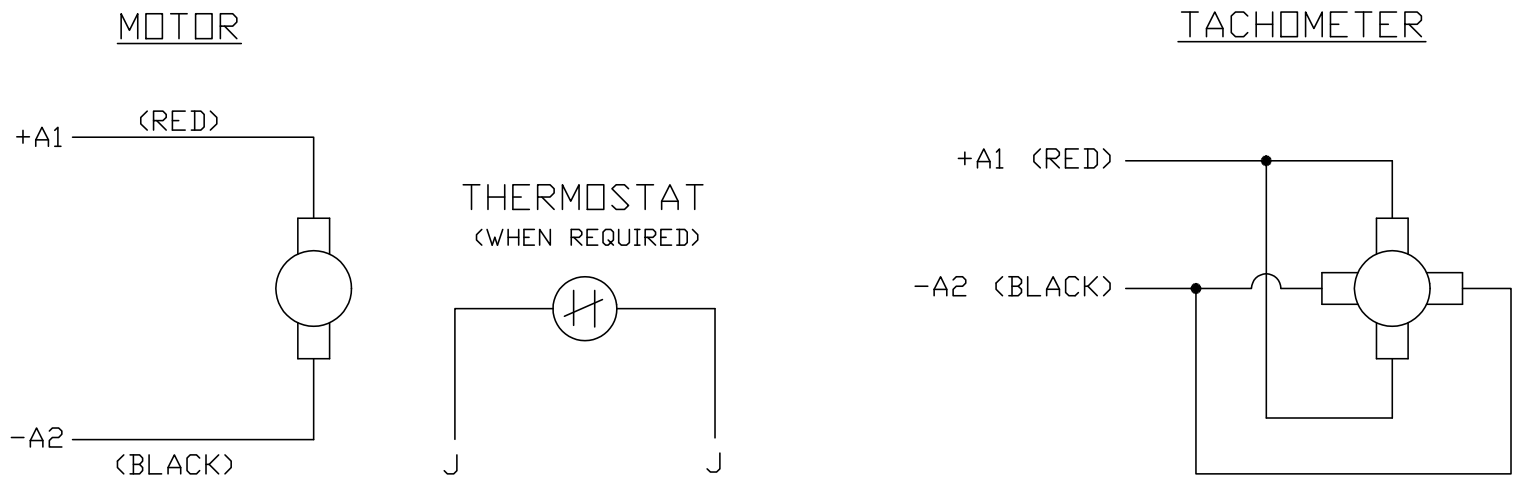

NOTES:

1. CCW ROTATION AS SHOWN FACING COMMUTATOR END. TO REVERSE MOTOR ROTATION OR TACHOMETER OUTPUT POLARITY INTERCHANGE LEADS A1(RED) & A2(BLACK)
2. LEAD COLORS FOR REFERENCE ONLY & NOT SPECIFIED BY THIS DRAWING. LEAD COLORS SPECIFIED BY LAYOUT DRAWING & BILL OF MATERIAL ONLY.

MATL: -			
REV: E	ADDED NOTE "LEAD COLORS FOR REFERENCE ONLY &...		
CD0194	SCALE: -	BY: CK	REVISED: 07/28/95
	FILE: AAA00004503		TDR: 0078737

BALDOR ELECTRIC Co.

CD TYPE P DC PERMANENT MAGNET MOTORS AND TACHOMETERS

CD0194