


Manifold Y Line Strainers

FEATURES

- EPDM gaskets.
- 316 stainless steel screens.
- 150 P.S.I. maximum.

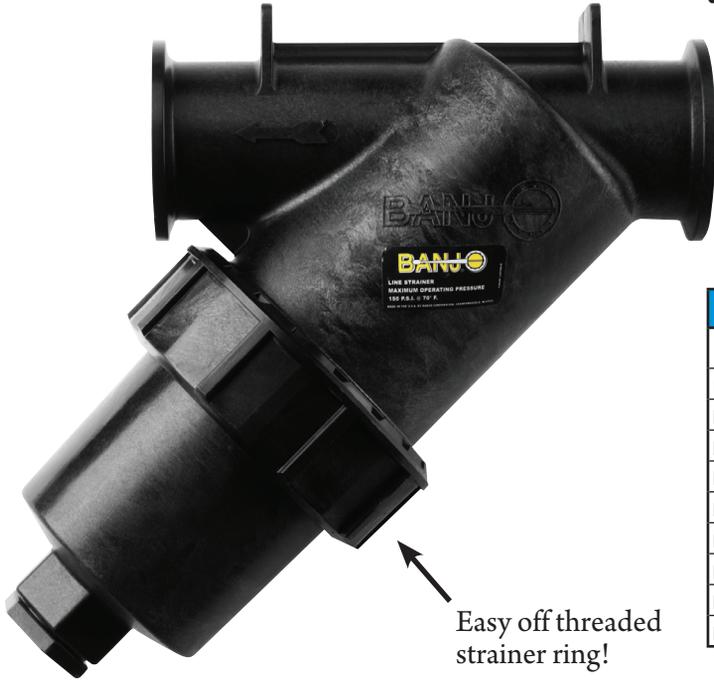

| 2" FULL PORT MANIFOLD Y LINE STRAINERS | | | | |
|--|--|---------|-----|----------|
| PART NO | DESCRIPTION | MAX PSI | QTY | PRICE |
| MLS222BC | 2" Full Port Flanged Body & Cap | 150 | 1 | \$64.71 |
| MLS222-04 | 2" Full Port Manifold Y Strainer w/4 Mesh Screen | 150 | 1 | \$129.59 |
| MLS222-08 | 2" Full Port Manifold Y Strainer w/8 Mesh Screen | 150 | 1 | \$129.59 |
| MLS222-10 | 2" Full Port Manifold Y Strainer w/10 Mesh Screen | 150 | 1 | \$129.59 |
| MLS222-16 | 2" Full Port Manifold Y Strainer w/16 Mesh Screen | 150 | 1 | \$129.59 |
| MLS222-30 | 2" Full Port Manifold Y Strainer w/30 Mesh Screen | 150 | 1 | \$129.59 |
| MLS222-50 | 2" Full Port Manifold Y Strainer w/50 Mesh Screen | 150 | 1 | \$129.59 |
| MLS222-80 | 2" Full Port Manifold Y Strainer w/80 Mesh Screen | 150 | 1 | \$129.59 |
| MLS222-100 | 2" Full Port Manifold Y Strainer w/100 Mesh Screen | 150 | 1 | \$129.59 |



FEATURES

- EPDM gaskets.
- 304 stainless steel screens.
- 100 P.S.I. maximum.

| 3" MANIFOLD Y LINE STRAINERS | | | | |
|------------------------------|---|---------|-----|----------|
| PART NO | DESCRIPTION | MAX PSI | QTY | PRICE |
| MLS300-04 | 3" Manifold Y Strainer w/4 Mesh Screen | 100 | 1 | \$473.78 |
| MLS300-08 | 3" Manifold Y Strainer w/8 Mesh Screen | 100 | 1 | \$473.78 |
| MLS300-12 | 3" Manifold Y Strainer w/12 Mesh Screen | 100 | 1 | \$473.78 |
| MLS300-20 | 3" Manifold Y Strainer w/20 Mesh Screen | 100 | 1 | \$473.78 |
| MLS300-50 | 3" Manifold Y Strainer w/50 Mesh Screen | 100 | 1 | \$473.78 |

***WARNING:** 3" Polypropylene "Y" Strainer to be used on suction side or non-pressure side in all applications.

