

1"-3" Electric Manifold Valves

FEATURES

- 316 stainless steel ball & stem.
- Fiberglass reinforced polypropylene.
- Glass reinforced PTFE seats.
- FKM (viton type) or EPDM O-rings.
- 12-volt DC operated.
- 150 P.S.I. maximum pressure.
- Internally fused/automatic reset.
- Open/closed indicator.

Don't forget the manifold connections on pages 64 & 65.



3/4 to 1 1/4 SECOND RESPONSE TIME


1", 2" & 3" ON/OFF ELECTRIC MANIFOLD VALVES						
PART NO	DESCRIPTION	MAX PSI	PIPE SIZE	OPENING THRU BALL	QTY	PRICE
MEV100CF	1" Full Port Electric Valve	150	1"	1"	1	\$450.75
MEV200CF	2" Standard Port Electric Valve	150	2"	1 1/2"	1	\$660.75
MEV220CF	2" Full Port Electric Valve	150	2"	2"	1	\$697.45
MEV300CF	3" Full Port Electric Valve	150	3"	3"	1	\$1,901.81

4 SECOND RESPONSE TIME

1" & 2" REGULATING ELECTRIC MANIFOLD VALVES						
PART NO	DESCRIPTION	MAX PSI	PIPE SIZE	OPENING THRU BALL	QTY	PRICE
MEVR100CF	1" Full Port Electric Valve	150	1"	1"	1	\$624.04
MEVR200CF	2" Standard Port Electric Valve	150	2"	1 1/2"	1	\$785.54
MEVR220CF	2" Full Port Electric Valve	150	2"	2"	1	\$829.58

Note: 2 wire regulating and other response times available. Contact our Sales Team for part number and availability of valves.

On/Off Wiring Diagram

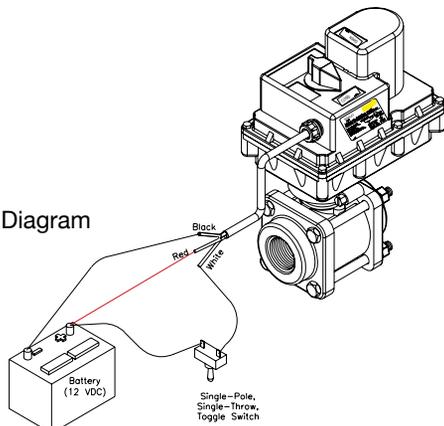

Regulating Wiring Diagram

