

# 3-Way Electric Valves

## 2" Full Port Threaded w/Flanged Inlet

### FEATURES

- 316 stainless steel ball & stem.
- Stainless steel hardware.
- Fiberglass reinforced polypropylene.
- Glass reinforced PTFE seats.
- FKM (viton type) or EPDM O-rings.
- 12-volt DC operated.
- 24-volt available in most models.
- 150 P.S.I. maximum pressure @ 70°F.
- Easily repairable.
- Open/closed indicator.

Don't forget the manifold connections for inlets on pages 66-69.



**Attention:**  
3-Way regulating valves are not shown, but are available.  
Standard 3-Way valves use the On/Off wiring diagram.



BOTTOM LOAD



SIDE LOAD

### 1 1/4 SECOND RESPONSE TIME

#### 2" FULL PORT BOTTOM LOAD ON/OFF ELECTRIC VALVES

PART NO	DESCRIPTION	MAX PSI	PIPE SIZE	OPENING THRU BALL	QTY	PRICE
EV204BLFP	2" Full Port Electric Valve	150	2"	2"	1	\$785.54

#### BOTTOM LOAD:

Directional flow right or left.  
Valve flow cannot be turned off.

### 1 1/4 SECOND RESPONSE TIME


#### 2" FULL PORT SIDE LOAD REGULATING ELECTRIC VALVES

PART NO	DESCRIPTION	MAX PSI	PIPE SIZE	OPENING THRU BALL	QTY	PRICE
EV204SLFP	2" Full Port Electric Valve	150	2"	2"	1	\$785.54

#### SIDE LOAD:

Directional flow right or left.  
Valve flow cannot be turned off.

On/Off Wiring Diagram

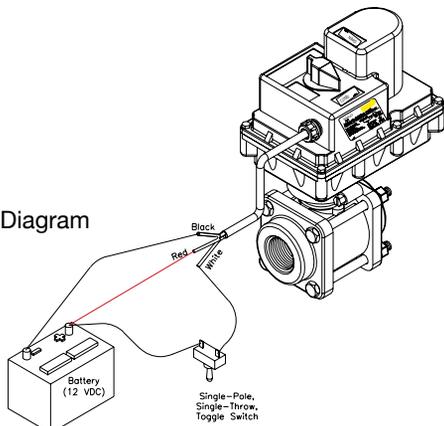

Regulating Wiring Diagram

