

Micro-Mill® Grinders

With Interchangeable Grinding Chambers


- Industry standard for grinding small samples from 20 to 50ml
- Temperature is maintained by means of built-in heat exchangers
- Cast aluminum body for long life



| Catalog No. | Description | Quantity / Pack |
|---|---|-----------------|
| MICRO-MILL® GRINDER with stainless steel blade and grinding chamber, and momentary hold-down switch. Operates only when switch is held down. | | |
| H37250-0000 | 115VAC, 60 Hz | 1 |
| MICRO-MILL® GRINDER with stainless steel blade and grinding chamber. 0-5 minute timer with "ON" position for continuous operation. | | |
| H37252-0000 | 115VAC, 60 Hz w/ electrical timer | 1 |
| H37252-0001 | 230VAC, 60 Hz w/ electrical timer | 1 |
| MICRO-MILL® GRINDER with hard, stellite faced blade and grinding chamber, with timer. | | |
| H37254-0000 | 115VAC, 60 Hz | 1 |
| Micro-Mill Grinder® Replacement Blades - For H37250 and H37252. No. 304 Stainless Steel blade. | | |
| H37257-0000 | Replacement Blade - 304 Stainless Steel | 1 |
| Micro-Mill Grinder® Hard-Faced Blade - For H37254. Stellite-faced blades for grinding samples up to hardness of stellite 6. | | |
| H37258-0000 | Hard-Faced Accessory Blade | 1 |

Micro-Mill® II Grinder

- Rapid, high speed milling of small samples from 20 to 50ml
- Additional grinding chambers available for processing multiple samples without cross contamination
- Economical polycarbonate construction; easy sample removal

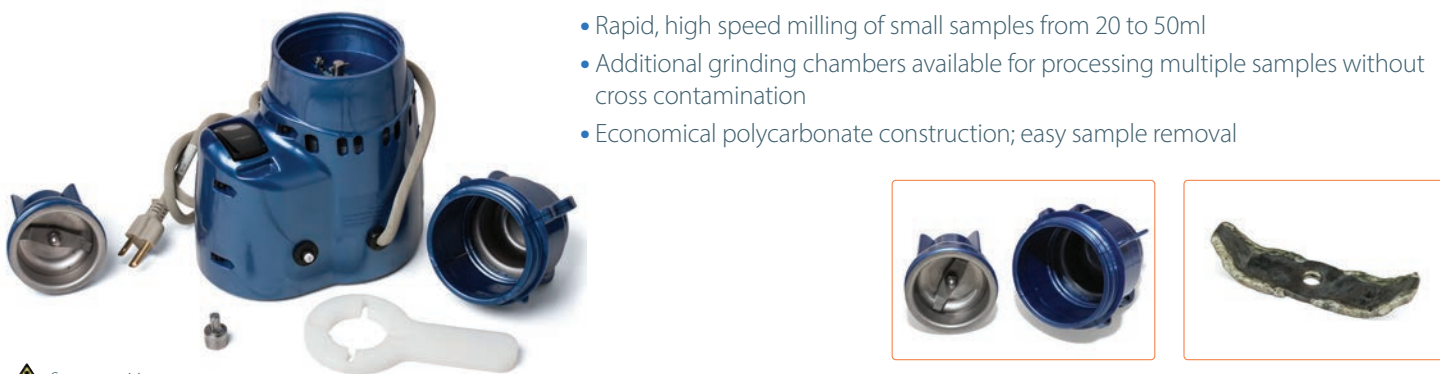

⚠ See page 44

| Catalog No. | Description | Quantity / Pack |
|-------------|---|-----------------|
| F37250-0010 | Micro-Mill® II Grinder, 115VAC, 60Hz | 1 |
| F37250-0011 | Micro-Mill® II Accessory Grinding Chamber | 1 |
| H37258-0000 | Hard-Faced Accessory Blade | 1 |

Note: Sterilized products are not returnable