


NEEDLE BEARING UNIVERSAL JOINTS - BOOTED

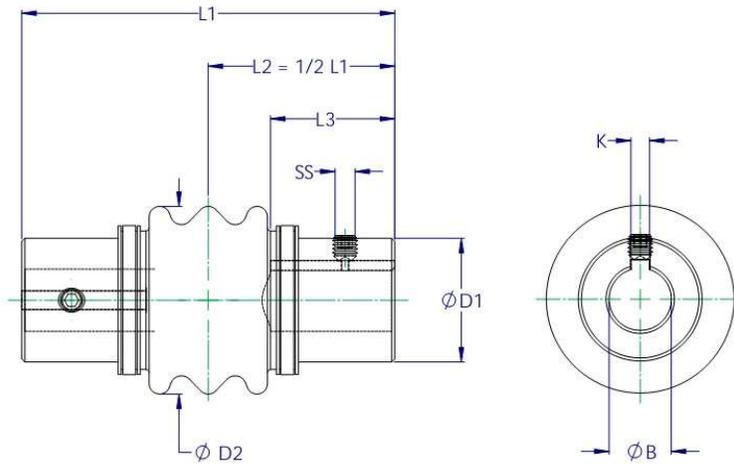

Legend

- ØD1: Outside Diameter
- ØD2: Boot Diameter
- ØB: Bore (Inside) Diameter
- L1: Overall Length
- L2: Yoke Length
- L3: Hub Length / Bore Depth
- K: Keyway
- SS: Setscrew

Booted Alloy Needle Bearing Universal Joints

Part Number	ØD1 Nominal (in)	ØD1 in [mm]	ØD2 in [mm]	ØB in [mm]	L1 in [mm]	L2 in [mm]	L3 in [mm]	K [in]	SS
NB-UJ750x3/8KB	3/4"	0.745 [18.92]	1.38 [35.1]	0.3750 [9.525]	2.688 [68.3]	1.344 [34.1]	0.95 [24.1]	3/32 x 3/64	Yes
NB-UJ1000x1/2KB	1"	0.995 [25.27]	1.53 [38.9]	0.5000 [12.700]	3.375 [85.7]	1.688 [42.9]	1.19 [30.2]	1/8 x 1/16	Yes
NB-UJ1250x5/8KB	1-1/4"	1.245 [31.62]	1.88 [47.8]	0.6250 [15.875]	3.750 [95.3]	1.875 [47.6]	1.25 [31.8]	3/16 x 3/32	Yes
NB-UJ1500x3/4KB	1-1/2"	1.495 [37.97]	2.25 [57.2]	0.7500 [19.050]	4.250 [108.0]	2.125 [54.0]	1.38 [34.9]	3/16 x 3/32	Yes
NB-UJ2000x1KB	2"	1.995 [50.67]	2.69 [68.3]	1.0000 [25.400]	5.500 [139.7]	2.750 [69.9]	1.70 [43.2]	1/4 x 1/8	Yes

Booted Stainless Steel Needle Bearing Universal Joints

Part Number	ØD1 Nominal (in)	ØD1 in [mm]	ØD2 in [mm]	ØB in [mm]	L1 in [mm]	L2 in [mm]	L3 in [mm]	K [in]	SS
SS-NBUJ750x3/8KB	3/4"	0.745 [18.92]	1.38 [35.1]	0.3750 [9.525]	2.688 [68.3]	1.344 [34.1]	0.95 [24.1]	3/32 x 3/64	Yes
SS-NBUJ1000x1/2KB	1"	0.995 [25.27]	1.53 [38.9]	0.5000 [12.700]	3.375 [85.7]	1.688 [42.9]	1.19 [30.2]	1/8 x 1/16	Yes
SS-NBUJ1250x5/8KB	1-1/4"	1.245 [31.62]	1.88 [47.8]	0.6250 [15.875]	3.750 [95.3]	1.875 [47.6]	1.25 [31.8]	3/16 x 3/32	Yes
SS-NB-UJ1500x3/4KB	1-1/2"	1.495 [37.97]	2.25 [57.2]	0.7500 [19.050]	4.250 [108.0]	2.125 [54.0]	1.38 [34.9]	3/16 x 3/32	Yes
SS-NBUJ2000x1KB	2"	1.995 [50.67]	2.69 [68.3]	1.0000 [25.400]	5.500 [139.7]	2.750 [69.9]	1.70 [43.2]	1/4 x 1/8	Yes

Yokes and fasteners stainless steel. [Metric values shown for reference only.]