




LV-10 / LV-10W

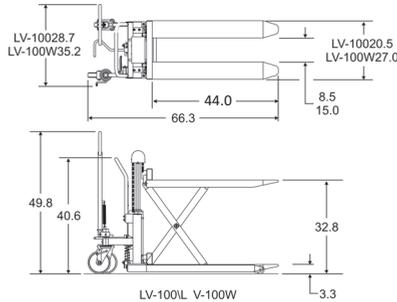


LV-100 / LV-100W

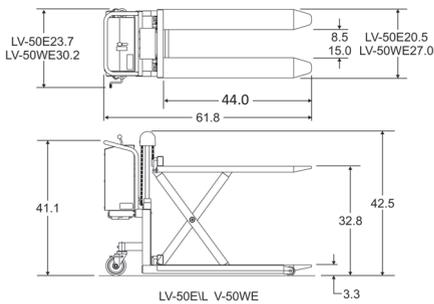

LV-50E / LV-50WE

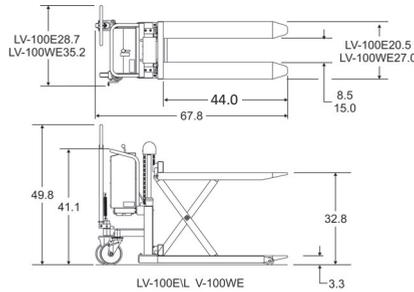

LV-100E / LV-100WE

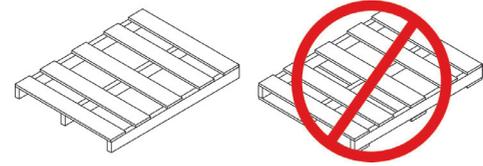

Standard Features

- Easily accessible hand and foot controls
- Precision, heavy duty steel construction throughout
- Twin heavy duty chains with 2-to-1 cylinder lifting ratio for improved cylinder wear and performance
- Lower captured roller channel provides increased and superior stability
- 2,200 lbs. capacity models have an offset 180 degree rotating steering handle
- Polyurethane wheels with roller bearings for better maneuverability
- Superior hydraulic system proven on a range of Bishamon lift products
- Caster with locking foot brake
- Travel of 29.5 inches
- 3.3 inch lowered fork height
- Quality baked enamel finish

Standard Features of DC LVE Models

- Easily accessible up/down lever hand control
- Built-in battery charger with timer
- Heavy-duty group 24 deep cycle battery
- Easy access battery disconnect plug
- Fused motor circuit

Selector Table for LV Series

Model	Travel (inches)	Capacity (lbs.)	Overall Fork Dimensions (in.)		Fork Height (in.)		Strokes or Lift Speed	Shipping Weight (lbs.)
			Width (OD)	Length	Lowered	Raised		
Manual Foot Pedal Pump Operated Models								
LV-10	29.5	1,000	20.5	44	3.3	32.8	35	300
LV-10W	29.5	1,000	27.0	44	3.3	32.8	35	325
LV-100	29.5	2,200	20.5	44	3.3	32.8	66	350
LV-100W	29.5	2,200	27.0	44	3.3	32.8	60	375
Manual Foot Pedal Pump Operated Models								
LV-50E	29.5	1,000	20.5	44	3.3	32.8	10	340
LV-50WE	29.5	1,000	27.0	44	3.3	32.8	10	370
LV-100E	29.5	2,200	20.5	44	3.3	32.8	18	440
LV-100WE	29.5	2,200	27.0	44	3.3	32.8	18	460

DISTRIBUTED BY:



Bishamon Industries Corporation

5651 East Francis Street
Ontario, California 91761-3601

(909) 390-0055 • (800) 358-8833
Fax (909) 390-0060

www.bishamon.com