


RADIAL BALL BEARINGS


METRIC 440C STAINLESS

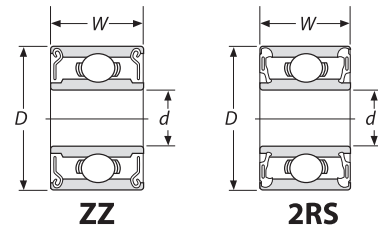

Bore mm d	OD mm D	Width mm W	Bearing Number	Basic Load Rating		Speed Rating		Weight (lb)
				Pounds		Grease	Oil	
				Dynamic	Static	RPM	RPM	
8	22	7	SS608	740	310	34000	40000	0.030
10	26	8	SS6000	1030	440	29000	34000	0.042
10	30	9	SS6200	1150	540	18000	30000	0.070
12	28	8	SS6001	1150	540	26000	30000	0.050
12	32	10	SS6201	1530	690	22000	26000	0.060
15	32	9	SS6002	1260	640	15000	28000	0.070
15	35	11	SS6202	1740	805	19000	23000	0.100
17	35	10	SS6003	1350	730	13000	26000	0.090
17	40	12	SS6203	2150	1080	12000	20000	0.150
20	42	12	SS6004	2110	1140	18000	21000	0.150
20	47	14	SS6204	2880	1490	11000	20000	0.240
25	47	12	SS6005	2260	1320	15000	18000	0.180
25	52	15	SS6205	3150	1770	9000	15000	0.280
30	55	13	SS6006	2970	1860	13000	15000	0.260
30	62	16	SS6206	4390	2540	11000	13000	0.440
35	62	14	SS6007	3600	2310	12000	14000	0.340
35	72	17	SS6207	5800	3400	9800	11000	0.630
40	68	15	SS6008	3750	2590	10000	12000	0.420

* Cages and shields are constructed of 304 stainless. Larger sizes available upon request. Consult factory.

FLANGED INCH 440C STAINLESS

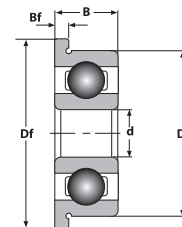

Bore in d	OD in D	Width B Open	Width B 1 or 2 Shields	Bearing Number	Flanged OD Df	Flanged Width Bf
.1250	0.3750	.1562	.1562	SSFR2	0.4400	.030
.1875	0.5000	.1562	.1960	SSFR3	0.5650	.042
.2500	0.6250	.1960	.1960	SSFR4	0.6900	.042
.3750	0.8750	.2188	.2812	SSFR6	0.9690	.062
.5000	1.1250	.2500	.3125	SSFR8	1.2250	.062

* Flanged R Series also available in non-stainless, 52100 steel.



www.bl-bearings.com