

L-P, B-P series

Pressed steel castors, medium-duty version, with top plate, wheel with pneumatic tyre

75–250 kg

Bracket: L/B series

- pressed steel, zinc-plated, blue-passivated, Cr6-free

Swivel bracket:


- double ball bearing in the swivel head
- strong central kingpin
- swivel head seal (exception: plate size 175x175 mm)
- minimum swivel head play and smooth rolling characteristic and increased service life due to the special dynamic Blickle riveting process

Wheel: P series

- tyre: pneumatic tyre with ribbed or zig-zag profile, hardness 60 Shore A, colour black, 2 or 4 ply rating
- rim: pressed steel, with welded tubular steel hub, zinc-plated, blue-passivated, Cr6-free
- swivel castors with brakes lose brake force if the tyre pressure is too low

Additional details:

- bracket series: page 91
- brakes: page 112–113
- wheel series: page 243
- bearing types: page 84–85

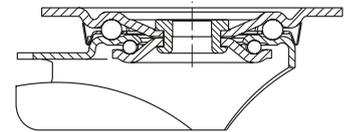

4

Swivel castors	Fixed castors	Swivel castor with "stop-top" brake	Wheel Ø [mm]	Tyre width [mm]	Load capacity [kg]	Bearing type	Total height [mm]	Plate size [mm]	Bolt hole spacing [mm]	Bolt hole Ø [mm]	Offset swivel castor [mm]	Profile type
L-P 200R	B-P 200R	L-P 200R-ST	200	50	75	roller bearing	235	140 x 110	105 x 75–80	11	65	R01
L-P 220R	B-P 220R	L-P 220R-ST	220	65	100	roller bearing	260	140 x 110	105 x 75–80	11	75	R01
L-P 222R	B-P 222R	L-P 222R-ST	220	65	100	roller bearing	260	140 x 110	105 x 75–80	11	75	B01
L-P 261R		L-P 261R-ST	260	85	150	roller bearing	308	175 x 175	140 x 140	15	78	R01
	B-P 261R		260	85	150	roller bearing	308	220 x 130	190 x 75	15	–	R01
L-P 263R		L-P 263R-ST	260	85	150	roller bearing	308	175 x 175	140 x 140	15	78	B02
	B-P 263R		260	85	150	roller bearing	308	220 x 130	190 x 75	15	–	B02
L-P 265R		L-P 265R-ST	260	85	250	roller bearing	308	175 x 175	140 x 140	15	78	R01
	B-P 265R		260	85	250	roller bearing	308	220 x 130	190 x 75	15	–	R01
L-P 267R		L-P 267R-ST	260	85	250	roller bearing	308	175 x 175	140 x 140	15	78	B02
	B-P 267R		260	85	250	roller bearing	308	220 x 130	190 x 75	15	–	B02

Profile types: R = ribbed profile, B = zig-zag profile, see page 248 for image

Versions / options



	with non-marking grey tyre	with puncture-proof, foam-filled tyres	directional lock (separate) 1 x 360°	castors with puncture-proof soft rubber wheels
Technical description page	52		115	62
Product code suffix	-SG	-AG	RI-05.03	L / B / BH-VW series
Available for	all	upon request	wheel Ø 200 mm*	see page 205

* Only for swivel castors without brake or swivel castor with "stop-top" brake upon request