

L-VW, B-VW, BH-VW series

Pressed steel castors, medium-duty version, with top plate, wheel with "Blickle Soft" soft rubber tyre

50–200 kg

Bracket: L/B/BH series

- pressed steel, zinc-plated, blue-passivated, Cr6-free

Swivel bracket:


- double ball bearing in the swivel head
- strong central kingpin (from wheel Ø 150 mm)
- swivel head seal (exception: plate size 175x175 mm)
- minimum swivel head play and smooth rolling characteristic and increased service life due to the special dynamic Blickle riveting process

Wheel: VW series

- tyre: soft rubber "Blickle Soft", hardness 50 Shore A, colour black (wheel Ø 260 mm with additional hard rubber core)
- rim: pressed steel, strong rim structure with tubular steel hub, bolted or pressed, zinc-plated, blue-passivated, Cr6-free

Additional details:

- bracket series: page 91
- brakes: page 112–113
- wheel series: page 204
- bearing types: page 84–85

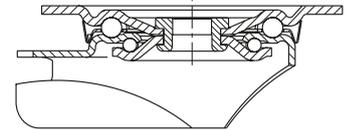

Swivel castors	Fixed castors	Swivel castors with "stop-fix" brake	Wheel Ø [mm]	Tyre width [mm]	Load capacity [kg]	Bearing type	Total height [mm]	Plate size [mm]	Bolt hole spacing [mm]	Bolt hole Ø [mm]	Offset swivel castor [mm]
L-VW 125R	B-VW 125R	L-VW 125R-FI	125	37.5	50	roller bearing	150	100 x 85	80 x 60	9	38
L-VW 162R	B-VW 162R	L-VW 162R-FI	160	40	70	roller bearing	195	140 x 110	105 x 75–80	11	60
L-VW 202R	B-VW 202R	L-VW 202R-FI	200	50	100	roller bearing	235	140 x 110	105 x 75–80	11	65
L-VW 252R-3	BH-VW 252R	*	250	60	160	roller bearing	295	140 x 110	105 x 75–80	11	77
L-VW 260R		*	260	85	200	roller bearing	308	175 x 175	140 x 140	15	78
	B-VW 260R		260	85	200	roller bearing	308	220 x 130	190 x 75	15	–
L-VW 260K		*	260	85	200	ball bearing	308	175 x 175	140 x 140	15	78
	B-VW 260K		260	85	200	ball bearing	308	220 x 130	190 x 75	15	–

* "stop-top" brake version, see versions / options

Versions / options



	with non-marking grey tyre	with thread guard, pressed steel, zinc-plated	with "stop-top" brake	directional lock (separate) 1 x 360°	directional lock (separate) 1 x 360°	with steel foot guard
Technical description page	52	116	112	115	115	116
Product code suffix	-SG	-FA	-ST	RI-03.01	RI-05.03	-FS
Available for	wheel Ø 125–200 mm, others upon request	wheel Ø 125–250 mm	all	wheel Ø 125 mm**	wheel Ø 160–200 mm**	up to wheel Ø 250 mm upon request

** Only for swivel castors without brake or swivel castor with "stop-top" brake upon request