

LPXA-VPA, BPXA-VPA, LKPXA-VPA, BKPXA-VPA series
Stainless steel light-duty castors with top plate, wheel with solid rubber tyres




40–120 kg

- Bracket:** LPXA/BPXA, LKPXA/BKPXA series
- high-quality chromium-nickel steel (1.4301/ AISI 304), stainless steel, vibration-ground finishing
 - all parts including axle material are corrosion-resistant
- swivel bracket:
- double ball bearing in the swivel head
 - strong central kingpin
 - minimum swivel head play and smooth rolling characteristic and increased service life due to the special dynamic Blickle riveting process
 - synthetic “stop-fix” brake lever for series LPXA, steel brake lever for series LKPXA

- Wheel:** VPA series
- tyre: high-quality solid rubber, hardness 80 Shore A, colour grey, non-marking, non-staining
 - rim: high-quality nylon 6, impact resistant, colour black

- Additional details:**
- bracket series: page 96
 - brakes: page 112–113
 - wheel series: page 60
 - bearing types: page 84–85

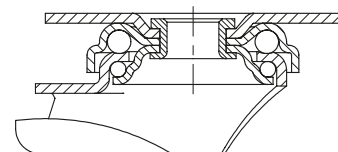

Swivel castors	Fixed castors	Swivel castors with “stop-fix” brake	Wheel Ø [mm]	Wheel width [mm]	Load capacity [kg]	Bearing type	Total height [mm]	Plate size [mm]	Bolt hole spacing [mm]	Bolt hole Ø [mm]	Offset swivel castor [mm]
LPXA-VPA 50G	BPXA-VPA 50G	LPXA-VPA 50G-FI	50	18	40	plain bore	71	60 x 60	38 x 38 / 48 x 48	6.2	23
LPXA-VPA 75G	BPXA-VPA 75G	LPXA-VPA 75G-FI	75	25	60	plain bore	100	60 x 60	38 x 38 / 48 x 48	6.2	29
LKPXA-VPA 80G	BKPXA-VPA 80G	LKPXA-VPA 80G-FI	80	25	80	plain bore	111	90 x 66	75 x 45 / 61 x 51	8.5	40
LKPXA-VPA 101G	BKPXA-VPA 101G	LKPXA-VPA 101G-FI	100	32	110	plain bore	136	90 x 66	75 x 45 / 61 x 51	8.5	40
LKPXA-VPA 125G	BKPXA-VPA 125G	LKPXA-VPA 125G-FI	125	25	100	plain bore	161	90 x 66	75 x 45 / 61 x 51	8.5	40
LKPXA-VPA 126G	BKPXA-VPA 126G	LKPXA-VPA 126G-FI	125	32	120	plain bore	161	90 x 66	75 x 45 / 61 x 51	8.5	40

8

Versions / options



illustration with plastic brake pedal, colour black

illustration with plastic brake pedal, colour grey

Technical description page

Product code suffix

Available for

series LPXA...-FI as standard	series LKPXA...-FI as standard
-------------------------------	--------------------------------