

LI-POHI, B-POHI, LIK-POHI, BK-POHI series

Heat-resistant pressed steel castors, top plate,
with heat-resistant

Blickle TempLine® Performance thermoplastic wheel



 150–350 kg

 -25 °C to +250 °C

Bracket: LI/B, LIK/BK series

- pressed steel, zinc-plated, blue-passivated, Cr6-free

Swivel bracket:

- double ball bearing in the swivel head (series LIK without central kingpin, with heat-resistant swivel head seal)
- smooth rolling characteristic and low wear, increased service life
- swivel head play is set specifically for high-temperature applications
- highly heat-resistant grease


Wheel: POHI series

- highly heat-resistant thermoplastic, impact resistant, hardness 85 Shore D, colour dark grey
- operating temperature: -25 °C to +250 °C

Additional details:

- bracket series: page 97–98
- brakes: page 112–113
- wheel series: page 458
- bearing types: page 84–85

 **Blickle**
TempLine® Performance

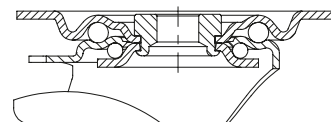

Swivel castors	Fixed castors	Swivel castors with "stop-fix" brake	Wheel Ø [mm]	Wheel width [mm]	Load capacity up to +70 °C [kg]	Bearing type	Total height [mm]	Plate size [mm]	Bolt hole spacing [mm]	Bolt hole Ø [mm]	Offset swivel castor [mm]
LI-POHI 81G	B-POHI 81G	LI-POHI 81G-FI	80	32	150	plain bore	102	100 x 85	80 x 60	9	38
LI-POHI 100G	B-POHI 100G	LI-POHI 100G-FI	100	30	150	plain bore	125	100 x 85	80 x 60	9	36
LIK-POHI 102G-1	BK-POHI 102G-1	LIK-POHI 102G-1-FI	100	38	250	plain bore	130	100 x 85	80 x 60	9	45
LIK-POHI 102HK-1	BK-POHI 102HK-1	LIK-POHI 102HK-1-FI	100	38	250	ball bearing	130	100 x 85	80 x 60	9	45
LI-POHI 125G	B-POHI 125G	LI-POHI 125G-FI	125	40	150	plain bore	150	100 x 85	80 x 60	9	38
LIK-POHI 125G-1	BK-POHI 125G-1	LIK-POHI 125G-1-FI	125	40	300	plain bore	155	100 x 85	80 x 60	9	48
LIK-POHI 125HK-1	BK-POHI 125HK-1	LIK-POHI 125HK-1-FI	125	40	350	ball bearing	155	100 x 85	80 x 60	9	48
LI-POHI 150G	B-POHI 150G	LI-POHI 150G-FI	150	50	350	plain bore	190	140 x 110	105 x 75–80	11	60
LI-POHI 150HK	B-POHI 150HK	LI-POHI 150HK-FI	150	50	350	ball bearing	190	140 x 110	105 x 75–80	11	60
LI-POHI 200G	B-POHI 200G	LI-POHI 200G-FI	200	50	350	plain bore	235	140 x 110	105 x 75–80	11	65
LI-POHI 200HK	B-POHI 200HK	LI-POHI 200HK-FI	200	50	350	ball bearing	235	140 x 110	105 x 75–80	11	65

Load capacity may be reduced in temperatures over +70 °C, see page 458.

Versions / options



with PTFE coated stainless steel axle tube

Technical description page	117
Product code suffix	-XAT
Available for	Ø 80–125 mm plain bore versions upon request