

# LRA-POA, BRA-POA, LKRA-POA, BKRA-POA series

## Light duty castors with bolt hole, with nylon wheel

70–120 kg

**Bracket:** LRA/BRA, LKRA/BKRA series  
 • pressed steel, zinc-plated, blue-passivated, Cr6-free

**Swivel bracket:**

- double ball bearing in the swivel head
- strong central kingpin
- minimum swivel head play and smooth rolling characteristic and increased service life due to the special dynamic Blickle riveting process
- synthetic “stop-fix” brake lever for series LRA, steel brake lever for series LKRA

**Wheel:** POA series


- high-quality nylon 6, impact resistant, hardness 70 Shore D, colour black

**Additional details:**

- bracket series: page 86
- brakes: page 112–113
- wheel series: page 143
- bearing types: page 84–85



1

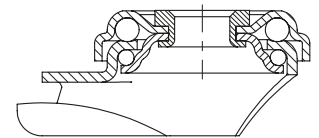

Swivel castors	Fixed castors	Swivel castors with “stop-fix” brake	Wheel Ø [mm]	Wheel width [mm]	Load capacity [kg]	Bearing type	Total height [mm]	Plate Ø [mm]	Bolt hole Ø [mm]	Offset swivel castor [mm]
LRA-POA 35G		LRA-POA 35G-RA *	35	25	75	plain bore	50	43	11	15
LRA-POA 50G	BRA-POA 50G	LRA-POA 50G-FI **	50	18	75	plain bore	69	43	11	23
LKRA-POA 52G		LKRA-POA 52G-RA *	50	29	120	plain bore	70	57	13	29
LRA-POA 75G	BRA-POA 75G	LRA-POA 75G-FI **	75	23	75	plain bore	98	43	11	29
LKRA-POA 80G	BKRA-POA 80G	LKRA-POA 80G-FI	80	32	120	plain bore	108	57	13	40
LKRA-POA 80G-11		LKRA-POA 80G-11-FI	80	32	120	plain bore	108	57	11	40
LRA-POA 102G		LRA-POA 102G-FI **	100	22	70	plain bore	121	43	11	33
LKRA-POA 100K	BKRA-POA 100K	LKRA-POA 100K-FI	100	30	120	ball bearing (C)	133	57	13	40
LKRA-POA 100K-11		LKRA-POA 100K-11-FI	100	30	120	ball bearing (C)	133	57	11	40
LKRA-POA 100G	BKRA-POA 100G	LKRA-POA 100G-FI	100	32	120	plain bore	133	57	13	40
LKRA-POA 100G-11		LKRA-POA 100G-11-FI	100	32	120	plain bore	133	57	11	40
LKRA-POA 125K	BKRA-POA 125K	LKRA-POA 125K-FI	125	30	120	ball bearing (C)	158	57	13	40
LKRA-POA 125K-11		LKRA-POA 125K-11-FI	125	30	120	ball bearing (C)	158	57	11	40
LKRA-POA 125G	BKRA-POA 125G	LKRA-POA 125G-FI	125	32	120	plain bore	158	57	13	40
LKRA-POA 125G-11		LKRA-POA 125G-11-FI	125	32	120	plain bore	158	57	11	40
LKRA-POA 150G	BKRA-POA 150G	LKRA-POA 150G-FI	150	32	110	plain bore	182	57	13	40
LKRA-POA 150G-11		LKRA-POA 150G-11-FI	150	32	110	plain bore	182	57	11	40

\* “Radstop” brake version

\*\* Synthetic brake lever, see image below

For stainless steel versions, see page 396

### Versions / options



	with synthetic brake lever	“Radstop” wheel brake	with threaded pin M10 x 30 M12 x 30	with plug-in pin Ø 11 x 30.5	with synthetic expander fitting	with metal expander fitting	buffers
Technical description page			104	105	105	105	116
Product code suffix			-GS10 / -GS12	-ES	see page 148	see page 148	AG / ARG series
Available for	series LRA...-FI as standard	series LRA Ø 35 mm series LKRA Ø 50 mm	-GS10: series LRA -GS12: series LKRA	series LRA swivel castors***	swivel castors bolt hole Ø 11 mm (with exception of Ø 35 mm)	swivel castors bolt hole Ø 11 mm (with exception of Ø 35 mm)	see page 148

\*\*\* Synthetic castor socket for round tubes see page 148