

3" Core Materials - Wire and Cable Labels

B-412 Polypropylene Tags

Color: White **Finish:** Matte

Thick polypropylene material used for wire, cable and inventory identification. Offers high print legibility and high tensile strength.

 


Figure 13

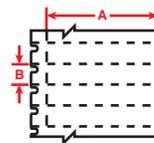


Figure 16



Diagram	Catalog #	Material	Finish	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Pkg	Rec. Ribbon
Fig. 16	THT-150-412-1	Polypropylene Tag	Matte	White	1.938 (49.2)	0.375 (9.5)	-	1	1,000	R6200
Fig. 13	THT-33-412-1	Polypropylene Tag	Matte	White	3.000 (76.2)	6.000 (152.4)	3.000 (76.2)	1	2 rolls of 500	R6202

B-508 Nomex® Wire and Cable Tags

Thermal transfer and dot matrix printable wire and cable bundle tag for harsh environments. Excellent tear, heat and solvent resistance. Meets the following industry specifications: SAE AS 81531, RoHS compliant. Tested per ASTM E162, ASTM E662.

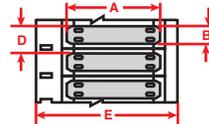


Figure 61



Note: The parts below are compatible with the i7100 and PR Plus printers only.

Diagram	Catalog #	Material	Finish	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Vert. Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Pkg	Rec. Ribbon	Rec. Printer
Fig. 61	HSNX-400-2-WT	Nomex® Tag	Matte	White	2.200 (55.8)	0.410 (10.4)	0.622 (15.79)	3.250 (82.55)	2,500	R4300	PR+300
Fig. 61	HSNX-400-2-WT-S	Nomex® Tag	Matte	White	2.200 (55.8)	0.410 (10.4)	0.622 (15.79)	3.250 (82.55)	250	R4300	PR+300
Fig. 61	HSNX-800-2-WT	Nomex® Tag	Matte	White	2.00 (50.8)	0.800 (10.160)	1.012 (25.70)	3.250 (82.55)	2,500	R4300	PR+300
Fig. 61	HSNX-800-2-WT-S	Nomex® Tag	Matte	White	2.00 (50.8)	0.800 (10.160)	1.012 (25.70)	3.250 (82.55)	250	R4300	PR+300
Fig. 61	HSNX-400-2-YL	Nomex® Tag	Matte	Yellow	2.200 (55.8)	0.410 (10.4)	0.622 (15.79)	3.250 (82.55)	2,500	R4300	PR+300
Fig. 61	HSNX-400-2-YL-S	Nomex® Tag	Matte	Yellow	2.200 (55.8)	0.410 (10.4)	0.622 (15.79)	3.250 (82.55)	250	R4300	PR+300
Fig. 61	HSNX-800-2-YL	Nomex® Tag	Matte	Yellow	2.00 (50.8)	0.800 (10.160)	1.012 (25.70)	3.250 (82.55)	2,500	R4300	PR+300
Fig. 61	HSNX-800-2-YL-S	Nomex® Tag	Matte	Yellow	2.00 (50.8)	0.800 (10.160)	1.012 (25.70)	3.250 (82.55)	250	R4300	PR+300

Nomex® is a registered trademark of DuPont.

B-7643 Heatex™ Cable Markers

Polyurethane tag material for dot matrix and thermal transfer printing. Low-halogen material that is RoHS compliant.

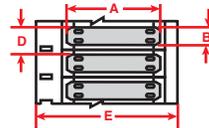


Figure 61



Note: The parts below are compatible with the i7100 and PR Plus printers only.

Diagram	Catalog #	Material	Finish	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Pkg	Rec. Ribbon
Fig. 61	HSCM-2400-0.390-WT	Polyurethane	Matte	White	2.362 (60.0)	0.394 (10.0)	1	1,000	R6002
Fig. 61	HSCM-3000-0.500-WT	Polyurethane	Matte	White	2.953 (75.0)	0.394 (10.0)	1	1,000	R6002
Fig. 61	HSCM-3000-0.625-WT	Polyurethane	Matte	White	2.953 (75.0)	0.591 (15.0)	1	1,000	R6002
Fig. 61	HSCM-3000-1-WT	Polyurethane	Matte	White	2.953 (75.0)	0.984 (25.0)	1	500	R6002
Fig. 61	HSCM-2400-0.390-YL	Polyurethane	Matte	Yellow	2.400 (61.0)	0.390 (9.0)	1	1,000	R6002
Fig. 61	HSCM-3000-0.625-YL	Polyurethane	Matte	Yellow	2.953 (75.0)	0.591 (15.0)	1	1,000	R6002
Fig. 61	HSCM-3000-1-YL	Polyurethane	Matte	Yellow	2.953 (75.0)	0.984 (25.0)	1	500	R6002

B-390 DuraSleeve® Polypropylene Inserts

Printable, rigid inserts designed to be printed and affixed to a wire using extruded, clear PVC Wire Marking Carriers. Inserts are supplied roll-form formatted for thermal transfer printing.

DuraSleeve Printable Inserts

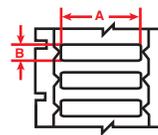


Figure 17

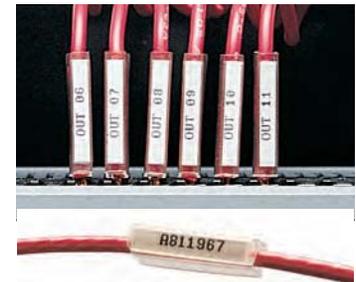


Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Pkg	Rec. Printer	Rec. Ribbon
Fig. 17	DSTHT-15-390-2.5	Polypropylene	White	0.591 (15.01)	0.163 (4.1)	2500	i7100, PR+	R6200
Fig. 17	DSTHT-30-390-2.5	Polypropylene	White	1.181 (30.0)	0.163 (4.1)	2500	i7100, PR+	R6200

0.590" Width Clear Carriers

Catalog #	Carrier Width Inch (mm)	Wire Outside Diameter Inch (mm)	Approx. Wire Gauge	Qty Per Pkg
DMC-1.3/3-15	0.590 (14.98)	0.051 (1.30) to 0.118 (3.00)	20-12	2000
DMC-2.5/5-15	0.590 (14.98)	0.098 (2.50) to 0.197 (5.00)	16-10	3000
DMC-4/10-15	0.590 (14.98)	0.157 (4.00) to 0.393 (10.00)	10-4	4000
DMC-8/16-15	0.590 (14.98)	0.315 (8.00) to 0.630 (16.00)	6-250	7500

1.180" Width Clear Carriers

Catalog #	Carrier Width Inch (mm)	Wire Outside Diameter Inch (mm)	Approx. Wire Gauge	Qty Per Pkg
DMC-1.3/3-30	1.180 (29.97)	0.051 (1.30) to 0.118 (3.00)	20-12	500
DMC-2.5/5-30	1.180 (29.97)	0.098 (2.50) to 0.197 (5.00)	16-10	100
DMC-4/10-30	1.180 (29.97)	0.157 (4.00) to 0.393 (10.00)	10-4	200
DMC-8/16-30	1.180 (29.97)	0.315 (8.00) to 0.630 (16.00)	6-250	250

Labels By Size Index page 300
Print Ribbons page 146
Material Guide page 264