

General Features & Benefits

- Reduces moisture in attic
- Lowers temperature of home in summer
- Metal flashing allows for nailing and hot tar application
- Mesh bird screen
- Built-in adjustable thermostat for automatic operation at your chosen temperature
- Mounts easily between rafters, installation template included



356BK



353, 35316 While supplies last

- Galvanized steel housing for added strength
- Combine with automatic shutter (model 433) to get optimum efficiency and performance



DD500W Remote In-Line Ventilator

Turn any ventilation fan into a humidity-sensing solution. Reduce mold and mildew to improve indoor air quality. Precision control enables desired humidity level to start the fan.

Powered Attic Ventilation Specifications

Model	Attic Sq Ft	AMPs	CFM*	RPM	Height	Diameter	Dome Material	Color
Roof Mount								
356BK	Up to 2285	8.0	1600	1500	8	23¼"	PVC	Brown/Black
Gable Mount								
353†	Up to 1460	3.4	1020 / 760**	1030	—	—	—	—
35316†**	Up to 2285	3.9	1600 / 1160**	1420	—	—	—	—

**While supplies last

Surface mount solar ventilation

For most roofs, our one-piece solar-powered attic ventilator (SPAV) is the perfect solution. Because our solar cells are highly efficient at capturing the sun's energy, there is no need for unsightly raised panels or tracking systems. Instead, what you see is a low profile ventilator in a contoured design that integrates well with the roof.



345SOBK



345SOWW While supplies last



Solar-powered Attic Ventilators—Surface, Curb, Remote and Gable


Broan Model	NuTone Model	CFM	Attic Max Cubic Ft.	ws	Color
345SOBK		537	3200	28	Black
345SOWW**		537	3200	28	Weathered Wood

**While supplies last



433 Automatic Shutter for Gable Mount Attic Ventilators While supplies last

Feature counter-balanced aluminum vanes that automatically open and close when the ventilator turns on and off. Better air flow than stationary attic louvers. Extruded aluminum frame fits flush with outside wall. Weather-tight closure. Easy to install.

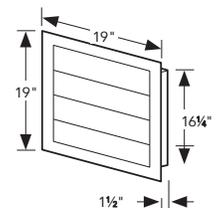

For use with Broan Models 353 and 35316.