



1PBS1/0, UV Rated Black Splice/Reducer, 2-Port, #14-1/0 AWG

By Burndy
Catalog # [1PBS1/0](#)

UV Rated Covering, Oxide inhibitor pre-installed. In-Line Splice Reducer.
#14-1/0 AWG, 1 wire each end.

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Application


For Indoor Use Only, Copper Or Stranded Aluminum

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - UL Listed Direct	No
Burial	
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - AL Str Size	• 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0
Conductor - AL Str Size Range	14 AWG - 1/0 AWG
Conductor - Copper Str Size	• 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG

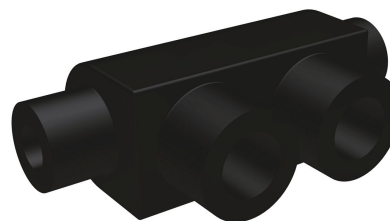

Conductor Size	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	14 AWG - 1/0 AWG

Configuration

Physical Attribute - Number of Screws	2
Number Of Ports	2
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	35.1 mm
Dimension - Height inch	1.38 in
Dimension - Height fraction	1.375 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	74 mm
Width	0.91 in
Dimension - Width fraction	91/100 in
Dimension - Screw Size inch	7/16
Length	2.91 in
Dimension - Width mm	23 mm
Dimension - Width inch	0.91 in
Height	1.38 in
Dimension - Length Overall inch	2.91 in
Dimensions	2.91 in x 0.91 in x 1.38 in

Force Related

Installation Torque Recommended	120 in-lb
---------------------------------	-----------

General

Product Family	MECHANICAL
Insulation Type	Plastisol
Trade Name	UNITAP™
Material - Hardware	Aluminum
Insulation	Y
Plated	No
Sub Brand	UNITAP
Product Type	Run/Tap
UPC	781810295922
Type	BIBS, Multi-Port
Hex Key	3/16
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810295922

UPC 14 Digit GTIN00781810295922

Logistics

Minimum Pack Quantity	1
Pallet Quantity	9600
Carton Quantity	100

Operational

Temperature Rating	194° F
--------------------	--------

Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)



A Hubbell brand