



1PBS2, UV Rated Black Splice/Reducer, 2-Port, #14-2 AWG

By Burndy
Catalog # [1PBS2](#)

UV Rated Covering. Oxide inhibitor pre-installed. In-Line Splice Reducer. #14-2 AWG, 1 wire each end.

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Application


For Indoor Use Only, Copper Or Stranded Aluminum

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	• 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG
Conductor - AL Str Size Range	14 AWG - 2 AWG
Conductor - Copper Str Size	• 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG

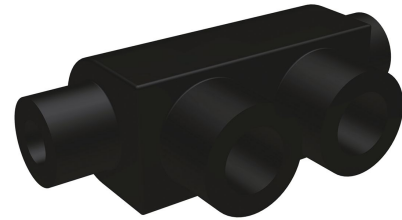

Conductor Size	• 3 AWG • 2 AWG
Conductor Type	14-2 AWG • AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	14 AWG - 2 AWG

Configuration

Physical Attribute - Number of Screws	2
Number Of Ports	2
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	31 mm
Dimension - Height inch	1.22 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	60 mm
Width	0.75 in
Dimension - Width fraction	3/4 in
Dimension - Screw Size inch	5/16
Length	2.38 in
Dimension - Width mm	19 mm
Dimension - Width inch	0.75 in
Height	1.22 in
Dimension - Length Overall inch	2.38 in
Dimensions	2.38 in x 0.75 in x 1.22 in

Force Related

Installation Torque Recommended in-lb	45 in-lb
---------------------------------------	----------

General

Insulation Type	Plastisol
Trade Name	UNITAP™
Material - Hardware	Aluminum

Insulation	Y
Plated	N
Sub Brand	UNITAP
UPC	781810329658
Type	BIBS, Multi-Port
Hex Key	1/8
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810329658
UPC 14 Digit GTIN	00781810329658

Logistics

Pallet Quantity	9600
Carton Quantity	100

Operational

Temperature Rating	194° F
--------------------	--------

Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)



A Hubbell brand