



1PBS350, UV Rated Black Splice/Reducer, 2-Port, 10-350 kcmil

By Burndy
Catalog # [1PBS350](#)

UV Rated Covering, Oxide inhibitor pre-installed. In-Line Splice Reducer.
#10 AWG-350 kcmil, 1 wire each end.

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Application


For Indoor Use Only, Copper Or Stranded Aluminum

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	• 10 AWG
	• 9 AWG
	• 8 AWG
	• 7 AWG
	• 6 AWG
	• 5 AWG
	• 4 AWG
	• 3 AWG
	• 2 AWG
	• 1 AWG
	• 1/0
	• 2/0 AWG
	• 3/0 AWG
	• 4/0 AWG
	• 250 kcmil
	• 300 kcmil
	• 350 kcmil
Conductor - AL Str Size Range	10 AWG - 350 kcmil
Conductor - Copper Str Size	• 10 AWG
	• 9 AWG

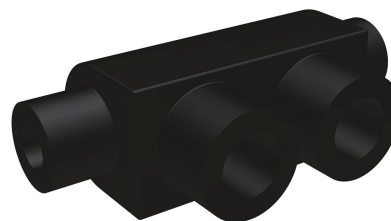

- 8 AWG
 - 7 AWG
 - 6 AWG
 - 5 AWG
 - 4 AWG
 - 3 AWG
 - 2 AWG
 - 1 AWG
 - 1/0
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 300 kcmil
 - 350 kcmil
- Conductor Size 10 AWG-350 KCMIL
- Conductor Type
- AL C Str-Size
 - CU C Str-Size
- Conductor - Copper Str Size Range 10 AWG - 350 kcmil

Configuration

Physical Attribute - Number of Screws	2
Number Of Ports	2
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	59.7 mm
Dimension - Height inch	2.35 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	118 mm
Width	1.34 in
Dimension - Width fraction	1-17/50 in
Dimension - Screw Size inch	5/16
Length	4.63 in
Dimension - Width mm	34 mm
Dimension - Width inch	1.34 in
Height	2.35 in
Dimension - Length Overall inch	4.63 in
Dimensions	4.63 in x 1.34 in x 2.35 in

Force Related

Installation Torque Recommended 275 in-lb
in-lb

General

Product Family MECHANICAL
Insulation Type Plastisol
Trade Name UNITAP™
Material - Hardware Aluminum
Insulation Y
Plated No
Sub Brand UNITAP
Product Type Run/Tap
UPC 781810295908
Type BIBS, Multi-Port
Hex Key 5/16



A Hubbell brand

Material Aluminum
Plating Type Unplated
UPC 12 Digit 781810295908
UPC 14 Digit GTIN 00781810295908

Logistics

Minimum Pack Quantity 1
Pallet Quantity 2160
Carton Quantity 60

Operational

Temperature Rating 194° F

Product Assets

[Catalog \[English\]](#)
[Catalog \[English\]](#)