




1PL2/05, UV Rated Black, 1-Sided, 5-Port,
#14-2/O AWG

By Burndy
Catalog # 1PL2/05

UV Rated Covering, Oxide inhibitor pre-installed, Same-Side, 5-Port Tap, #14-2/O AWG

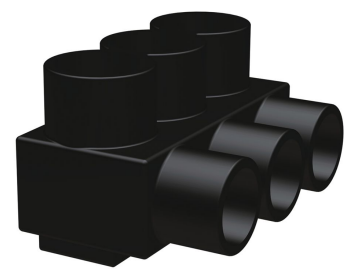

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
UL Listed	Yes
Certification - UL Listed Direct Burial	No

Conductor

Conductor - Copper Str Size	• 14 AWG
	• 12 AWG
	• 10 AWG
	• 9 AWG
	• 8 AWG
	• 7 AWG
	• 6 AWG
	• 5 AWG
	• 4 AWG
	• 3 AWG
	• 2 AWG
	• 1 AWG
	• 1/O
	• 2/O AWG
Conductor - AL Str Size	• 14 AWG
	• 12 AWG
	• 10 AWG
	• 9 AWG
	• 8 AWG
	• 7 AWG
	• 6 AWG
	• 5 AWG
	• 4 AWG
	• 3 AWG
	• 2 AWG

- 1 AWG
- 1/O
- 2/O AWG

Conductor - AL Str Size Range	14 AWG - 2/O AWG
Conductor Size	14-2/O AWG
Conductor - Copper Str Size Range	14 AWG - 2/O AWG
Conductor Type	• AL C Str-Size • CU C Str-Size

Configuration

Physical Attribute - Number of Screws	5
Connector Type	Multi Tap
Number Of Ports	5

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - L Length Overall mm	90 mm
Dimension - Height fraction	1.375 in
Dimension - Height inch	1.38 in
Package Height	0.000 in
Dimension - Height mm	35.1 mm
Dimension - Screw Size inch Width	7/16 1.31 in
Dimension - Width inch	1.31 in
Dimension - Width mm Length	33 mm 3.53 in
Dimension - Length Overall inch	3.53 in
Height	1.38 in
Dimensions	3.53 in x 1.31 in x 1.38 in

Force Related

Installation Torque Recommended in-lb	120 in-lb
---------------------------------------	-----------

General

Material - Hardware	Aluminum
---------------------	----------

Insulation Type	Plastisol
Trade Name	UNITAP™
Insulation	Y
Plated	N
UPC 12 Digit	781810286869
UPC 14 Digit GTIN	00781810286869
Material	Aluminum
Hex Key	3/16
Plating Type	Unplated
UPC	781810286869

Minimum Pack Quantity	1
Carton Quantity	100
Pallet Quantity	1

Operational

Temperature Rating	194° F
--------------------	--------

Product Assets

[Catalog \[English\]](#)

[Catalog \[English\]](#)

Logistics



A Hubbell brand