


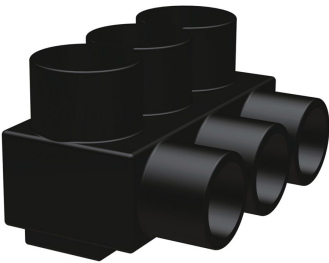

1PL2504, UV Rated Black, 1-Sided, 3-Port, #10 AWG-250 kcmil

By Burndy
Catalog # 1PL2504

UV Rated Covering, Oxide inhibitor pre-installed, Same-Side, 4-Port Tap, #10 AWG-250 kcmil



Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Application

For Indoor Use Only, Copper Or Stranded Aluminum

Specifications

Certification - UL Recognized	No
Buy American Compliant	Yes
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	• Buy America Compliant (All status valid till December 2026) • Buy American Act Compliant (All status valid till December 2026) • BABA Compliant (All status valid till December 2026)
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG
-------------------------	--

Conductor - AL Str Size Range	• 3/0 AWG • 4/0 AWG • 250 kcmil
Conductor - Copper Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil
Conductor Size	10 AWG-250 KCMIL
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	10 AWG - 250 kcmil

Configuration

Physical Attribute - Number of Screws	4
Number Of Ports	4
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	54.1 mm
Dimension - Height inch	2.13 in
Dimension - Height fraction	2-1/8 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	99 mm
Width	2.07 in
Dimension - Screw Size inch	5/8

Length	3.91 in	UPC	781810286906
Dimension - Width mm	53 mm	Type	BIBS, Multi-Port
Dimension - Width inch	2.07 in	Hex Key	5/16
Height	2.13 in	Material	Aluminum
Dimension - Length Overall	3.91 in	Plating Type	Unplated
inch		UPC 12 Digit	781810286906
Dimensions	3.91 in x 2.07 in x 2.13 in	UPC 14 Digit GTIN	00781810286906

Force Related

Installation Torque	275 in-lb
Recommended in-lb	

General

Insulation Type	Plastisol
Trade Name	UNITAP™
Material - Hardware	Aluminum
Insulation	Y
Physical Attribute - Screw Type	Allen
Plated	N
Sub Brand	UNITAP

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1728
Carton Quantity	24

Operational

Temperature Rating	194° F
--------------------	--------

Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)



A Hubbell brand