


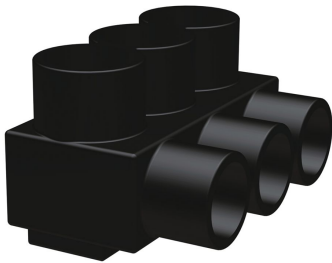

1PL2508, UV Rated Black, 1-Sided, 8-Port,
#10 AWG-250 kcmil

By Burndy
Catalog # 1PL2508

UV Rated Covering, Oxide inhibitor pre-installed, Same-Side, 8-Port Tap, #10 AWG-250 kcmil



Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
UL Listed	Yes
Certification - UL Listed Direct Burial	No

Conductor

Conductor Size	10 AWG-250 KCMIL
Conductor - Copper Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil
Conductor - Copper Str Size Range	10 AWG - 250 kcmil
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - AL Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG

- 5 AWG
- 4 AWG
- 3 AWG
- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil

Conductor - AL Str Size Range 10 AWG - 250 kcmil

Configuration

Physical Attribute - Number of Screws	8
Connector Type	Multi Tap
Number Of Ports	8

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Dimension - Width inch	2.07 in
Package Length	0.000 in
Dimension - Width mm	53 mm
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - L Length Overall mm	195 mm
Dimension - Height fraction	2-1/8 in
Dimension - Height inch	2.13 in
Package Height	0.000 in
Dimension - Height mm	54.1 mm
Length	7.66 in
Dimension - Screw Size inch	5/8
Dimension - Length Overall inch	7.66 in
Width	2.07 in
Height	2.13 in
Dimensions	7.66 in x 2.07 in x 2.13 in

Force Related

Installation Torque Recommended in-lb	275 in-lb
---------------------------------------	-----------

General

Material - Hardware	Aluminum
Physical Attribute - Screw Type	Allen
Insulation Type	Plastisol
Trade Name	UNITAP™
Plated	N
Insulation	Y
UPC 12 Digit	781810286913
UPC 14 Digit GTIN	00781810286913
Material	Aluminum
Hex Key	5/16
Plating Type	Unplated



A Hubbell brand

UPC781810286913

Logistics

Minimum Pack Quantity1

Operational

Temperature Rating194° F

Product Assets

[Catalog \[English\]](#)
[Catalog \[English\]](#)