


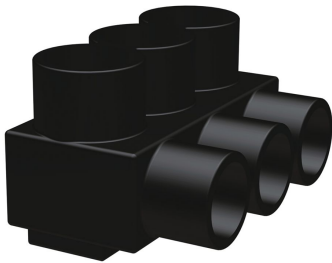

1PL3504, UV Rated Black, 1-Sided, 4-Port,
#10 AWG-350 kcmil

By Burndy
Catalog # 1PL3504

UV Rated Covering, Oxide inhibitor pre-installed, Same-Side, 4-Port Tap, #10 AWG-350 kcmil



Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Buy America(n) Qualified	BABA Compliant (All status valid till December 2026)
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil
Conductor - AL Str Size Range	10 AWG - 350 kcmil
Conductor - Copper Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG

- 5 AWG
 - 4 AWG
 - 3 AWG
 - 2 AWG
 - 1 AWG
 - 1/0
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 300 kcmil
 - 350 kcmil
- Conductor Size 10 AWG-350 KCMIL
- Conductor Type
- AL C Str-Size
 - CU C Str-Size

Conductor - Copper Str Size Range	10 AWG - 350 kcmil
-----------------------------------	--------------------

Configuration

Physical Attribute - Number of Screws	4
Number Of Ports	4
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	63.5 mm
Dimension - Height inch	2.50 in
Dimension - Height fraction	2-1/2 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	103 mm
Width	2.32 in
Dimension - Screw Size inch	11/16
Length	4.04 in
Dimension - Width mm	59 mm
Dimension - Width inch	2.32 in
Height	2.5 in
Dimension - Length Overall inch	4.04 in
Dimensions	4.04 in x 2.32 in x 2.5 in

Force Related

Installation Torque 275 in-lb
Recommended in-lb

General

Insulation Type Plastisol
Trade Name UNITAP™
Material - Hardware Aluminum
Insulation Y
Physical Attribute - Screw Type Allen
Plated N
UPC 781810286937
Hex Key 5/16
Material Aluminum
Plating Type Unplated



A Hubbell brand

UPC 12 Digit 781810286937
UPC 14 Digit GTIN 00781810286937

Logistics

Minimum Pack Quantity 5
Pallet Quantity 2304
Carton Quantity 24

Operational

Temperature Rating 194° F

Product Assets

[Catalog \[English\]](#)
[Catalog \[English\]](#)