


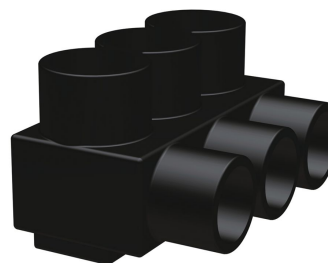

1PL3506, UV Rated Black, 1-Sided, 6-Port, #10 AWG-350 kcmil

By Burndy
Catalog # [1PL3506](#)

UV Rated Covering, Oxide inhibitor pre-installed, Same-Side, 6-Port Tap, #10 AWG-350 kcmil



Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil
Conductor - AL Str Size Range	10 AWG - 350 kcmil
Conductor - Copper Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG

- 3 AWG
- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil
- 300 kcmil
- 350 kcmil

Conductor Size	10 AWG-350 KCMIL
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	10 AWG - 350 kcmil

Configuration

Physical Attribute - Number of Screws	6
Number Of Ports	6
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	63.5 mm
Dimension - Height inch	2.50 in
Dimension - Height fraction	2-1/2 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	149 mm
Width	2.32 in
Dimension - Screw Size inch	11/16
Length	5.86 in
Dimension - Width mm	59 mm
Dimension - Width inch	2.32 in
Height	2.5 in
Dimension - Length Overall inch	5.86 in
Dimensions	5.86 in x 2.32 in x 2.5 in

Force Related

Installation Torque	275 in-lb	UPC 12 Digit	781810286951
Recommended in-lb		UPC 14 Digit GTIN	00781810286951
General		Logistics	
Insulation Type	Plastisol	Minimum Pack Quantity	5
Trade Name	UNITAP™	Pallet Quantity	864
Material - Hardware	Aluminum	Carton Quantity	24
Insulation	Y	Operational	
Physical Attribute - Screw Type	Allen	Temperature Rating	194° F
Plated	N	Product Assets	
UPC	781810286951	Catalog [English]	
Hex Key	5/16	Catalog [English]	
Material	Aluminum		
Plating Type	Unplated		



A Hubbell brand