


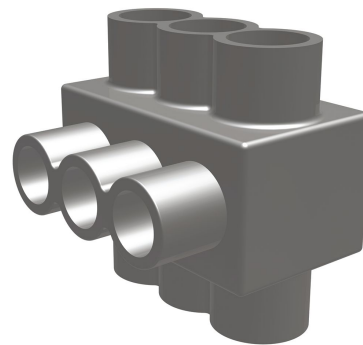

1PLD25012, UV Rated Black, 2-Side, 12-Port, 10 AWG-250 kcmil

By Burndy
Catalog # [1PLD25012](#)

UV Rated Covering, Oxide inhibitor pre-installed 2-Sided, 12-Port Tap, #10 AWG-250 kcmil



Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor Size	10 AWG-250 KCMIL
Conductor - AL Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil
Conductor - AL Str Size Range	10 AWG - 250 kcmil
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	10 AWG - 250 kcmil
Conductor - Copper Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG

- 6 AWG
- 5 AWG
- 4 AWG
- 3 AWG
- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil

Configuration

Physical Attribute - Number of Screws	12
Number Of Ports	12
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	54.1 mm
Length	11.41 in
Dimension - Height inch	2.13 in
Dimension - Height fraction	2.125 in
Package Weight	0.000 lb.
Dimension - Width mm	67 mm
Dimension - Width inch	2.64 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	290 mm
Height	2.13 in
Width	2.64 in
Dimension - Screw Size inch	5/8
Dimension - Length Overall inch	11.41 in
Dimensions	11.41 in x 2.64 in x 2.13 in

Force Related

Installation Torque	275 in-lb
Recommended in-lb	

General

Physical Attribute - Screw Type	Allen
Plated	N
Insulation Type	Plastisol
Trade Name	UNITAP™
Material - Hardware	Aluminum
UPC	781810287248
Insulation	Y
Hex Key	5/16
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810287248



A Hubbell brand

UPC 14 Digit GTIN00781810287248

Logistics

Minimum Pack Quantity1

Operational

Temperature Rating194° F

Product Assets

[Catalog \[English\]](#)
[Catalog \[English\]](#)