



1PLD2504, UV Rated Black, 2-Side, 4-Port,
#10 AWG-250 kcmil

By Burndy
Catalog # 1PLD2504

UV Rated Covering, Oxide inhibitor pre-installed 2-Sided, 4-Port
Tap, #10 AWG-250 kcmil

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Application


For Indoor Use Only, Copper Or Stranded Aluminum

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil
Conductor - AL Str Size Range	10 AWG - 250 kcmil
Conductor - Copper Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG

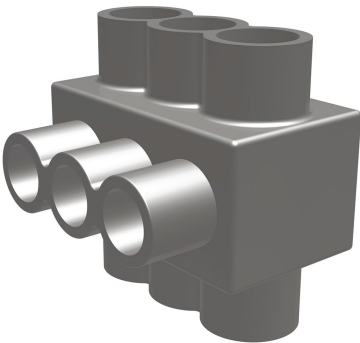

- 5 AWG
 - 4 AWG
 - 3 AWG
 - 2 AWG
 - 1 AWG
 - 1/0
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
- 10 AWG-250 KCMIL
- AL C Str-Size
 - CU C Str-Size

Conductor Size	10 AWG-250 KCMIL
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	10 AWG - 250 kcmil

Configuration

Physical Attribute - Number of Screws	4
Number Of Ports	4
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	54.1 mm
Dimension - Height inch	2.13 in
Dimension - Height fraction	2.125 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	99 mm
Width	2.64 in
Dimension - Width fraction	2-16/25 in
Dimension - Screw Size inch	5/8
Length	3.91 in
Dimension - Width mm	67 mm
Dimension - Width inch	2.64 in
Height	2.13 in
Dimension - Length Overall inch	3.91 in
Dimensions	3.91 in x 2.64 in x 2.13 in

Force Related

Installation Torque 275 in-lb
Recommended in-lb

General

Insulation Type Plastisol
Trade Name UNITAP™
Material - Hardware Aluminum
Insulation Y
Physical Attribute - Screw Type Allen
Plated N
Sub Brand UNITAP
UPC 781810287194
Type BIBD, Multi-Port
Hex Key 5/16



A Hubbell brand

Material Aluminum
Plating Type Unplated
UPC 12 Digit 781810287194
UPC 14 Digit GTIN 00781810287194

Logistics

Pallet Quantity 1344
Carton Quantity 24

Operational

Temperature Rating 194° F

Product Assets

[Catalog \[English\]](#)
[Catalog \[English\]](#)