


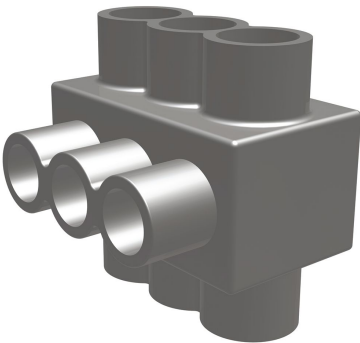

1PLD35010, UV Rated Black, 2-Side, 10-Port, 10 AWG-350 kcmil

By Burndy
Catalog # 1PLD35010

UV Rated Covering, Oxide inhibitor pre-installed 2-Sided, 10-Port Tap, #10 AWG-350 kcmil



Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	No
UL Listed	Yes
Certification - UL Listed Direct Burial	No

Conductor

Conductor Size	10 AWG-350 KCMIL
Conductor - Copper Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil
Conductor - Copper Str Size Range	10 AWG - 350 kcmil
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - AL Str Size	• 10 AWG • 9 AWG • 8 AWG

- 7 AWG
- 6 AWG
- 5 AWG
- 4 AWG
- 3 AWG
- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil
- 300 kcmil
- 350 kcmil

Conductor - AL Str Size Range 10 AWG - 350 kcmil

Configuration

Physical Attribute - Number of Screws	10
Connector Type	Multi Tap
Number Of Ports	10

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Dimension - Width inch	3.00 in
Package Length	0.000 in
Dimension - Width mm	76 mm
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - L Length Overall mm	241 mm
Dimension - Height fraction	2.5 in
Dimension - Height inch	2.50 in
Package Height	0.000 in
Dimension - Height mm	63.5 mm
Length	9.5 in
Dimension - Screw Size inch	11/16
Dimension - Length Overall inch	9.50 in
Width	3 in
Height	2.5 in
Dimensions	9.5 in x 3 in x 2.5 in

Force Related

Installation Torque	275 in-lb	Hex Key	5/16
Recommended in-lb		Plating Type	Unplated
		UPC	781810287316
General		Logistics	
Material - Hardware	Aluminum	Minimum Pack Quantity	1
Physical Attribute - Screw Type	Allen	Operational	
Insulation Type	Plastisol	Temperature Rating	194° F
Trade Name	UNITAP™	Product Assets	
Plated	N	Catalog [English]	
Insulation	Y	Catalog [English]	
UPC 12 Digit	781810287316		
UPC 14 Digit GTIN	00781810287316		
Material	Aluminum		



A Hubbell brand