


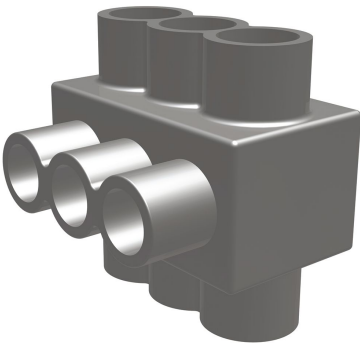

1PLD60012, UV Rated Black, 2-Side, 12-Port, #4 AWG-600 kcmil

By Burndy
Catalog # 1PLD60012

UV Rated Covering, Oxide inhibitor pre-installed 2-Sided, 12-Port Tap, #4 AWG-600 kcmil



Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil • 450 kcmil • 477 kcmil • 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil
Conductor - AL Str Size Range	4 AWG - 600 kcmil
Conductor - Copper Str Size	• 4 AWG • 3 AWG • 2 AWG

- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil
- 300 kcmil
- 350 kcmil
- 400 kcmil
- 450 kcmil
- 500 kcmil
- 550 kcmil
- 600 kcmil

Conductor Size	4 AWG-600 KCMIL
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	4 AWG - 600 kcmil

Configuration

Physical Attribute - Number of Screws	12
Number Of Ports	12
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	69.9 mm
Dimension - Height inch	2.75 in
Dimension - Height fraction	2.75 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	394 mm
Width	3 in
Dimension - Screw Size inch	13/16
Length	15.53 in
Dimension - Width mm	76 mm
Dimension - Width inch	3.00 in
Height	2.75 in
Dimension - Length Overall inch	15.53 in

Dimensions	15.53 in x 3 in x 2.75 in	UPC 14 Digit GTIN	00781810287408
General		Logistics	
Insulation Type	Plastisol	Minimum Pack Quantity	1
Trade Name	UNITAP™	Pallet Quantity	360
Material - Hardware	Aluminum	Carton Quantity	15
Insulation	Y	Operational	
Physical Attribute - Screw Type	Allen	Temperature Rating	194
Plated	N	Product Assets	
UPC	781810287408	Catalog [English]	
Hex Key	3/8	Catalog [English]	
Material	Aluminum		
Plating Type	Unplated		
UPC 12 Digit	781810287408		



A Hubbell brand