



**1PLD6004, UV Rated Black, 2-Sided, 4-Ports,
#4 AWG-600 kcmil**

By Burndy
Catalog # [1PLD6004](#)

UV Rated Covering, Oxide inhibitor pre-installed 2-Sided, 4-Port Tap, #4
AWG-600 kcmil

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Application


For Indoor Use Only, Copper Or Stranded Aluminum

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil • 450 kcmil • 477 kcmil • 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil
-------------------------	---

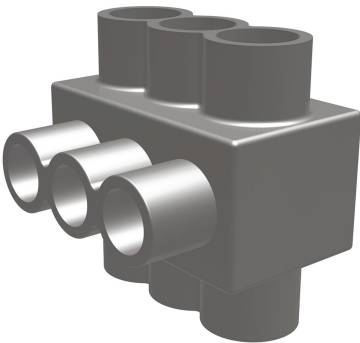

Conductor - AL Str Size Range	4 AWG - 600 kcmil
Conductor - Copper Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil • 550 kcmil • 600 kcmil
Conductor Size	4 AWG-600 KCMIL
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	4 AWG - 600 kcmil

Configuration

Physical Attribute - Number of Screws	4
Number Of Ports	4
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	69.9 mm
Dimension - Height inch	2.75 in
Dimension - Height fraction	2.75 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	134 mm
Width	3 in
Dimension - Screw Size inch	13/16
Length	5.28 in
Dimension - Width mm	76 mm
Dimension - Width inch	3.00 in
Height	2.75 in

Dimension - Length Overall inch 5.28 in
Dimensions 5.28 in x 3 in x 2.75 in

Force Related

Installation Torque Recommended 375 LBS/in
in-lb

General

Product Family MECHANICAL
Insulation Type Plastisol
Trade Name UNITAP™
Material - Hardware Aluminum
Insulation Y
Physical Attribute - Screw Type Allen
Plated No
Sub Brand UNITAP
Product Type Run/Tap
UPC 781810287354

Type BIBD, Multi-Port
Hex Key 3/8
Material Aluminum
Plating Type Unplated
UPC 12 Digit 781810287354
UPC 14 Digit GTIN 00781810287354

Logistics

Minimum Pack Quantity 1
Pallet Quantity 600
Carton Quantity 40

Operational

Temperature Rating 194

Product Assets

[Catalog \[English\]](#)
[Catalog \[English\]](#)



A Hubbell brand