


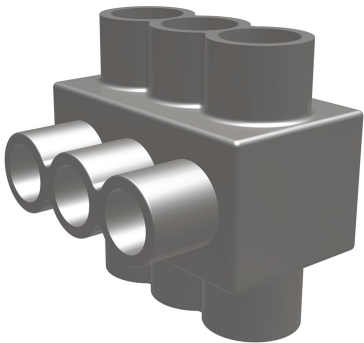

1PLD6005, UV Rated Black, 2-Sided, 5-Ports, #4 AWG-600 kcmil

By Burndy
Catalog # 1PLD6005

UV Rated Covering, Oxide inhibitor pre-installed 2-Sided, 5-Port Tap, #4 AWG-600 kcmil



Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil • 450 kcmil • 477 kcmil • 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil
Conductor - AL Str Size Range	4 AWG - 600 kcmil
Conductor - Copper Str Size	• 4 AWG • 3 AWG • 2 AWG

- 1 AWG
 - 1/0
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 300 kcmil
 - 350 kcmil
 - 400 kcmil
 - 450 kcmil
 - 500 kcmil
 - 550 kcmil
 - 600 kcmil
- Conductor Size 4 AWG-600 KCMIL
- Conductor Type
- AL C Str-Size
 - CU C Str-Size
- Conductor - Copper Str Size Range 4 AWG - 600 kcmil

Configuration

Physical Attribute - Number of Screws	5
Number Of Ports	5
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	69.9 mm
Dimension - Height inch	2.75 in
Dimension - Height fraction	2.75 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	167
Width	3 in
Dimension - Screw Size inch Length	13/16 6.56 in
Dimension - Width mm	76 mm
Dimension - Width inch	3.00 in
Height	2.75 in
Dimension - Length Overall inch	6.56

Dimensions	6.56 in x 3 in x 2.75 in	Plating Type	Unplated
Force Related		UPC 12 Digit	781810287361
		UPC 14 Digit GTIN	00781810287361
Installation Torque	375 LBS/in	Logistics	
Recommended in-lb			
General			
	Minimum Pack Quantity	1	
Insulation Type	Plastisol	Pallet Quantity	600
Trade Name	UNITAP™	Carton Quantity	40
Material - Hardware	Aluminum	Operational	
Insulation	Y		
Physical Attribute - Screw Type	Allen	Temperature Rating	194
Plated	N	Product Assets	
UPC	781810287361		
Hex Key	3/8		
Material	Aluminum	Catalog [English]	
		Catalog [English]	



A Hubbell brand