



1PLD6008, UV Rated Black, 2-Sided, 8-Ports, #4 AWG-600 kcmil

By Burndy
Catalog # 1PLD6008

UV Rated Covering, Oxide inhibitor pre-installed 2-Sided, 8-Port Tap, #4 AWG-600 kcmil

Features


- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil • 450 kcmil • 477 kcmil • 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil
Conductor - AL Str Size Range	4 AWG - 600 kcmil
Conductor - Copper Str Size	• 4 AWG • 3 AWG • 2 AWG

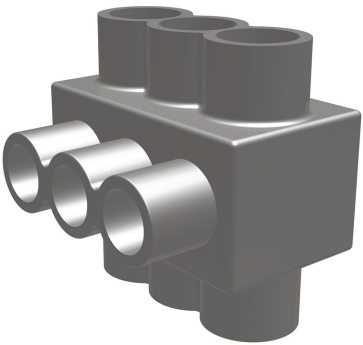

- 1 AWG
 - 1/0
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 300 kcmil
 - 350 kcmil
 - 400 kcmil
 - 450 kcmil
 - 500 kcmil
 - 550 kcmil
 - 600 kcmil
- Conductor Size 4 AWG-600 KCMIL
- Conductor Type
- AL C Str-Size
 - CU C Str-Size

Conductor - Copper Str Size Range 4 AWG - 600 kcmil

Configuration

Physical Attribute - Number of Screws	8
Number Of Ports	8
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	69.9 mm
Dimension - Height inch	2.75 in
Dimension - Height fraction	2.75 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	264 mm
Width	3 in
Dimension - Screw Size inch	13/16
Length	10.4 in
Dimension - Width mm	76 mm
Dimension - Width inch	3.00 in
Height	2.75 in
Dimension - Length Overall inch	10.40 in

Dimensions	10.4 in x 3 in x 2.75 in	Plating Type	Unplated	
Force Related		UPC 12 Digit	781810287385	
		UPC 14 Digit GTIN	00781810287385	
Installation Torque	375 LBS/in	Logistics		
Recommended in-lb			Minimum Pack Quantity	1
General			Pallet Quantity	300
		Carton Quantity	20	
	Insulation Type	Plastisol	Operational	
	Trade Name	UNITAP™		
	Material - Hardware	Aluminum		
	Insulation	Y	Temperature Rating	194
	Physical Attribute - Screw Type	Allen	Product Assets	
	Plated	N		
	UPC	781810287385		
Hex Key	3/8	Catalog [English]		
Material	Aluminum	Catalog [English]		



A Hubbell brand