




1PLM60012, UV Black, Mount, 1-Side, 12-Port, 4 AWG-600 kcmil

By Burndy

Catalog # [1PLM60012](#)

UV Rated Covering, Oxide inhibitor pre-installed, Mountable, 1-Sided, 12-Port Tap, #4 AWG-600 kcmil

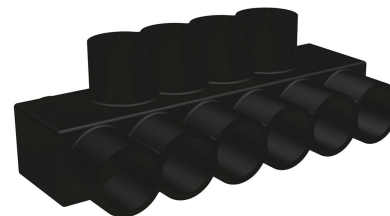

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	4 AWG-600 KCMIL
Conductor - AL Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil • 450 kcmil • 477 kcmil • 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil
Conductor - AL Str Size Range	4 AWG - 600 kcmil
Conductor Type	• AL C Str-Size • CU C Str-Size

Conductor - Copper Str Size Range 4 AWG - 600 kcmil

- Conductor - Copper Str Size
- 4 AWG
 - 3 AWG
 - 2 AWG
 - 1 AWG
 - 1/0 AWG
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 266 kcmil
 - 300 kcmil
 - 336 kcmil
 - 350 kcmil
 - 397 kcmil
 - 400 kcmil
 - 450 kcmil
 - 477 kcmil
 - 500 kcmil
 - 550 kcmil
 - 556 kcmil
 - 600 kcmil

Configuration

Physical Attribute - Number of Screws	14
Number Of Ports	12
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Dimension - Height mm	73.2 mm
Length	17.84 in
Dimension - Height inch	2.88
Dimension - Height fraction	2-7/8 in
Dimension - Width mm	60 mm
Dimension - Width inch	2.38
Dimension - L Length Overall mm	453
Height	2.88 in
Width	2.38 in
Dimension - Length Overall inch	17.84

Dimensions	17.84 in x 2.38 in x 2.88 in	Plating Type	Clear Plated
Force Related		UPC 12 Digit	781810308035
		UPC 14 Digit GTIN	00781810308035
Installation Torque	375 in-lb	Logistics	
Recommended in-lb			
General		Minimum Pack Quantity	1
		Operational	
Plated	Y		
Insulation Type	Plastisol	Temperature Rating	194° F
Trade Name	UNITAP™	Product Assets	
Material - Hardware	Aluminum		
UPC	781810308035	Catalog [English]	
Insulation	Y	Catalog [English]	
Material	Aluminum		



A Hubbell brand