


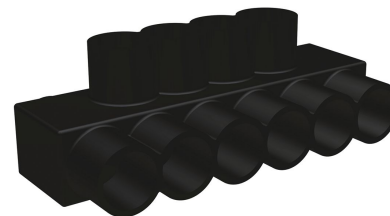

1PLM6004, UV Black, Mount, 1-Side, 4-Port, #4 AWG-600 kcmil

By Burndy
Catalog # [1PLM6004](#)

UV Rated Covering, Oxide inhibitor pre-installed, Mountable, 1-Sided, 4-Port Tap, #4 AWG-600 kcmil



Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	4 AWG-600 KCMIL
Conductor - AL Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil • 450 kcmil • 477 kcmil • 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil
Conductor - AL Str Size Range	4 AWG - 600 kcmil
Conductor Type	• AL C Str-Size • CU C Str-Size

Conductor - Copper Str Size Range 4 AWG - 600 kcmil

Conductor - Copper Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil • 450 kcmil • 477 kcmil • 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil
-----------------------------	---

Configuration

Physical Attribute - Number of Screws	6
Number Of Ports	4
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Dimension - Height mm	73.2 mm
Length	7.59 in
Dimension - Height inch	2.88
Dimension - Height fraction	2-7/8 in
Dimension - Width mm	60 mm
Dimension - Width inch	2.38
Dimension - L Length Overall mm	193
Height	2.88 in
Width	2.38 in
Dimension - Length Overall inch	7.59

Dimensions	7.59 in x 2.38 in x 2.88 in	UPC 12 Digit	781810308042
		UPC 14 Digit GTIN	00781810308042
Force Related		Logistics	
Installation Torque	375 in-lb	Minimum Pack Quantity	1
Recommended in-lb		Pallet Quantity	1
		Carton Quantity	1
General		Operational	
Plated	Y	Temperature Rating	194° F
Insulation Type	Plastisol	Product Assets	
Trade Name	UNITAP™	Catalog [English]	
Material - Hardware	Aluminum	Catalog [English]	
UPC	781810308042		
Insulation	Y		
Material	Aluminum		
Plating Type	Clear Plated		



A Hubbell brand