




1PLMD2/04, UV Black, Mount, 2-Sided, 4-Port, #14-2/0 AWG

By Burndy

Catalog # [1PLMD2/04](#)

UV Rated Covering, Oxide inhibitor pre-installed, Mountable, 2-Sided, 4-Port Tap, #14-2/0 AWG

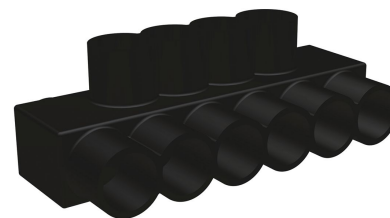

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	14-2/0 AWG
Conductor - AL Str Size	• 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG
Conductor - AL Str Size Range	14 AWG - 2/0 AWG
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	14 AWG - 2/0 AWG
Conductor - Copper Str Size	• 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG

- 7 AWG
- 6 AWG
- 5 AWG
- 4 AWG
- 3 AWG
- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG

Configuration

Physical Attribute - Number of Screws	6
Number Of Ports	4
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	38.1 mm
Length	3.95 in
Dimension - Height inch	1.5
Dimension - Height fraction	1-1/2 in
Package Weight	0.000 lb.
Dimension - Width mm	40 mm
Dimension - Width inch	1.56
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	100
Height	1.5 in
Width	1.56 in
Dimension - Length Overall inch	3.95
Dimensions	3.95 in x 1.56 in x 1.5 in

Force Related

Installation Torque Recommended in-lb	120 in-lb
---------------------------------------	-----------

General

Plated	Y
Insulation Type	Plastisol

Trade Name	UNITAP™	Minimum Pack Quantity	1
Material - Hardware	Aluminum	Pallet Quantity	4500
UPC	781810307526	Carton Quantity	100
Insulation	Y		
Material	Aluminum	Operational	
Plating Type	Clear Plated	Temperature Rating	194° F
UPC 12 Digit	781810307526		
UPC 14 Digit GTIN	00781810307526		

Logistics

Product Assets

[Catalog \[English\]](#)

[Catalog \[English\]](#)



A Hubbell brand