




1PLMD2504, UV Black, Mount, 2-Side, 4-Port, 10 AWG-250 kcmil

By Burndy  
Catalog # 1PLMD2504

UV Rated Covering, Oxide inhibitor pre-installed, Mountable, 2-Sided, 4-Port Tap, #10 AWG-250 kcmil

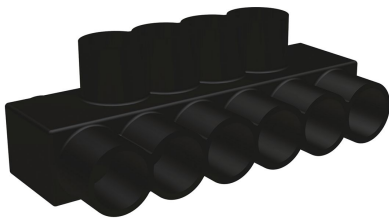

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

- 3 AWG
- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil

Specifications

|                                         |     |
|-----------------------------------------|-----|
| Standards - RoHS Compliance Status      | CM  |
| Certification - UL Listed Direct Burial | No  |
| UL Listed                               | Yes |
| Certification - CSA Approved            | Yes |

Conductor

|                                   |                                                                                                                                                                                                                                                                                                  |
|-----------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Conductor Size                    | 10 AWG-250 KCMIL                                                                                                                                                                                                                                                                                 |
| Conductor - AL Str Size           | <ul style="list-style-type: none"><li>• 10 AWG</li><li>• 9 AWG</li><li>• 8 AWG</li><li>• 7 AWG</li><li>• 6 AWG</li><li>• 5 AWG</li><li>• 4 AWG</li><li>• 3 AWG</li><li>• 2 AWG</li><li>• 1 AWG</li><li>• 1/0</li><li>• 2/0 AWG</li><li>• 3/0 AWG</li><li>• 4/0 AWG</li><li>• 250 kcmil</li></ul> |
| Conductor - AL Str Size Range     | 10 AWG - 250 kcmil                                                                                                                                                                                                                                                                               |
| Conductor Type                    | <ul style="list-style-type: none"><li>• AL C Str-Size</li><li>• CU C Str-Size</li></ul>                                                                                                                                                                                                          |
| Conductor - Copper Str Size Range | 10 AWG - 250 kcmil                                                                                                                                                                                                                                                                               |
| Conductor - Copper Str Size       | <ul style="list-style-type: none"><li>• 10 AWG</li><li>• 9 AWG</li><li>• 8 AWG</li><li>• 7 AWG</li><li>• 6 AWG</li><li>• 5 AWG</li><li>• 4 AWG</li></ul>                                                                                                                                         |

Configuration

|                                       |           |
|---------------------------------------|-----------|
| Physical Attribute - Number of Screws | 6         |
| Number Of Ports                       | 4         |
| Connector Type                        | Multi Tap |

Current

|                   |       |
|-------------------|-------|
| Voltage - Maximum | 600 V |
|-------------------|-------|

Dimensions

|                                 |                             |
|---------------------------------|-----------------------------|
| Package Height                  | 0.000 in                    |
| Dimension - Height mm           | 56.6 mm                     |
| Length                          | 5.53 in                     |
| Dimension - Height inch         | 2.13                        |
| Dimension - Height fraction     | 2-1/4 in                    |
| Package Weight                  | 0.000 lb.                   |
| Dimension - Width mm            | 67 mm                       |
| Dimension - Width inch          | 2.64                        |
| Package Length                  | 0.000 in                    |
| Package Width                   | 0.000 in                    |
| Dimension - L Length Overall mm | 140                         |
| Height                          | 2.13 in                     |
| Width                           | 2.64 in                     |
| Dimension - Length Overall inch | 5.53                        |
| Dimensions                      | 5.53 in x 2.64 in x 2.13 in |

General

|                     |              |
|---------------------|--------------|
| Plated              | N            |
| Insulation Type     | Plastisol    |
| Trade Name          | UNITAP™      |
| Material - Hardware | Aluminum     |
| UPC                 | 781810307588 |
| Insulation          | Y            |
| Hex Key             | 5/16         |

|                       |                |                                   |        |
|-----------------------|----------------|-----------------------------------|--------|
| Material              | Aluminum       | Carton Quantity                   | 1      |
| Plating Type          | Unplated       |                                   |        |
| UPC 12 Digit          | 781810307588   | <b>Operational</b>                |        |
| UPC 14 Digit GTIN     | 00781810307588 | Temperature Rating                | 194° F |
| <b>Logistics</b>      |                | <b>Product Assets</b>             |        |
| Minimum Pack Quantity | 1              | <a href="#">Catalog [English]</a> |        |
| Pallet Quantity       | 1              | <a href="#">Catalog [English]</a> |        |

