




1PLMD35010, UV Black, Mount, 2-Sided, 10-Port, 10 AWG-350

By Burndy

Catalog # [1PLMD35010](#)

UV Rated Covering, Oxide inhibitor pre-installed, Mountable, 2-Sided, 10-Port Tap, #10 AWG-350 kcmil

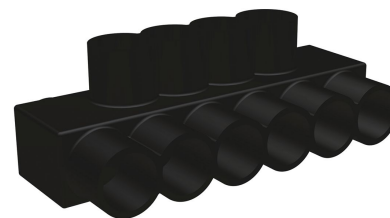

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	10 AWG-350 KCMIL
Conductor - AL Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil
Conductor - AL Str Size Range	10 AWG - 350 kcmil
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	10 AWG - 350 kcmil
Conductor - Copper Str Size	• 10 AWG • 9 AWG

- 8 AWG
- 7 AWG
- 6 AWG
- 5 AWG
- 4 AWG
- 3 AWG
- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil
- 300 kcmil
- 350 kcmil

Configuration

Physical Attribute - Number of Screws	12
Number Of Ports	10
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Dimension - Height mm	66.5 mm
Length	11.91 in
Dimension - Height inch	2.63
Dimension - Height fraction	2-5/8 in
Dimension - Width mm	76 mm
Dimension - Width inch	3
Dimension - L Length Overall mm	303
Height	2.63 in
Width	3 in
Dimension - Length Overall inch	11.92
Dimensions	11.91 in x 3 in x 2.63 in

Force Related

Installation Torque Recommended in-lb	275 in-lb
---------------------------------------	-----------

General

Physical Attribute - Screw Type	Allen
Plated	Y
Insulation Type	Plastisol
Trade Name	UNITAP™
Material - Hardware	Aluminum
UPC	781810307625
Insulation	Y
Material	Aluminum
Plating Type	Clear Plated
UPC 12 Digit	781810307625
UPC 14 Digit GTIN	00781810307625

Logistics

Minimum Pack Quantity	1
-----------------------	---

Operational

Temperature Rating	194° F
--------------------	--------

Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)



A Hubbell brand