




1PLMD35012, UV Black, Mount, 2-Sided, 12-Port, 10 AWG-350

By Burndy

Catalog # [1PLMD35012](#)

UV Rated Covering, Oxide inhibitor pre-installed, Mountable, 2-Sided, 12-Port Tap, #10 AWG-350 kcmil

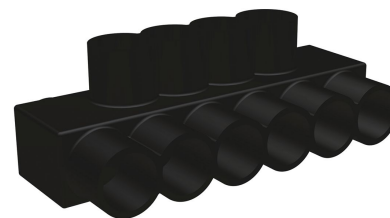

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	10 AWG-350 KCMIL
Conductor - AL Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil
Conductor - AL Str Size Range	10 AWG - 350 kcmil
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	10 AWG - 350 kcmil
Conductor - Copper Str Size	• 10 AWG • 9 AWG

- 8 AWG
- 7 AWG
- 6 AWG
- 5 AWG
- 4 AWG
- 3 AWG
- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil
- 300 kcmil
- 350 kcmil

Configuration

Physical Attribute - Number of Screws	14
Number Of Ports	12
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	66.5 mm
Length	13.92 in
Dimension - Height inch	2.63
Dimension - Height fraction	2-5/8 in
Package Weight	0.000 lb.
Dimension - Width mm	76 mm
Dimension - Width inch	3
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	354
Height	2.63 in
Width	3 in
Dimension - Length Overall inch	13.92
Dimensions	13.92 in x 3 in x 2.63 in

Force Related

Installation Torque	275 in-lb	UPC 12 Digit	781810307632
Recommended in-lb		UPC 14 Digit GTIN	00781810307632
General		Logistics	
Physical Attribute - Screw Type	Allen	Minimum Pack Quantity	1
Plated	Y	Operational	
Insulation Type	Plastisol	Temperature Rating	194° F
Trade Name	UNITAP™	Product Assets	
Material - Hardware	Aluminum	Catalog [English]	
UPC	781810307632	Catalog [English]	
Insulation	Y		
Material	Aluminum		
Plating Type	Clear Plated		



A Hubbell brand