




1PLMD3504, UV Black, Mount, 2-Sided, 4-Port, 10 AWG-350

By Burndy

Catalog # [1PLMD3504](#)

UV Rated Covering, Oxide inhibitor pre-installed, Mountable, 2-Sided, 4-Port Tap, #10 AWG-350 kcmil

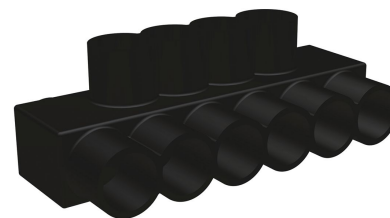

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - AL Str Size	• 8 AWG • 6 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil
Conductor - AL Str Size Range	8 AWG-350 kcmil
Conductor - Copper Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG

- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil
- 300 kcmil
- 350 kcmil

Conductor Size	10 AWG-350 KCMIL
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	10 AWG - 350 kcmil

Configuration

Physical Attribute - Number of Screws	6
Number Of Ports	4
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	63.5 mm
Dimension - Height inch	2.50 in
Dimension - Height fraction	2.5 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	142 mm
Width	3 in
Length	5.92 in
Dimension - Width mm	76 mm
Dimension - Width inch	3.00 in
Height	2.63 in
Dimension - Length Overall inch	5.61 in
Dimensions	5.92 in x 3 in x 2.63 in

Force Related

Installation Torque Recommended in-lb	375 LBS/in
---------------------------------------	------------

General

Insulation Type	Plastisol
Insulation	Y
Physical Attribute - Screw Type	Allen
Plated	N
UPC	781810307649
Hex Key	1/3
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810307649
UPC 14 Digit GTIN	00781810307649

Logistics

Minimum Pack Quantity	5
Pallet Quantity	675
Carton Quantity	25

Operational

Temperature Rating	194
--------------------	-----

Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)



A Hubbell brand