




1PLMD3508, UV Black, Mount, 2-Sided, 8-Port, 10 AWG-350

By Burndy
Catalog # 1PLMD3508

UV Rated Covering, Oxide inhibitor pre-installed, Mountable, 2-Sided, 8-Port Tap, #10 AWG-350 kcmil

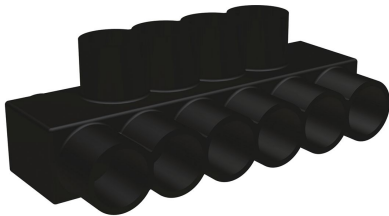

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	10 AWG-350 KCMIL
Conductor - AL Str Size	• 8 AWG • 6 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil
Conductor - AL Str Size Range	8 AWG-350 kcmil
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	10 AWG - 350 kcmil
Conductor - Copper Str Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG

- 6 AWG
- 5 AWG
- 4 AWG
- 3 AWG
- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil
- 300 kcmil
- 350 kcmil

Configuration

Physical Attribute - Number of Screws	10
Number Of Ports	8
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Dimension - Height mm	63.5 mm
Length	9.92 in
Dimension - Height inch	2.50 in
Dimension - Height fraction	2.5 in
Dimension - Width mm	76 mm
Dimension - Width inch	3.00 in
Dimension - L Length Overall mm	235 mm
Height	2.63 in
Width	3 in
Dimension - Length Overall inch	9.25 in
Dimensions	9.92 in x 3 in x 2.63 in

Force Related

Installation Torque Recommended in-lb	375 LBS/in
---------------------------------------	------------

General

Physical Attribute - Screw Type Plated	Allen N
--	---------

Insulation Type	Plastisol
UPC	781810307663
Insulation	Y
Hex Key	1/3
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810307663
UPC 14 Digit GTIN	00781810307663

Logistics



A Hubbell brand

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)

[Catalog \[English\]](#)