




1PLMD6004, UV Black, Mount, 2-Side, 4-Port, 4 AWG-600

By Burndy

Catalog # [1PLMD6004](#)

UV Rated Covering, Oxide inhibitor pre-installed, Mountable, 2-Sided, 4-Port Tap, #4 AWG-600 kcmil

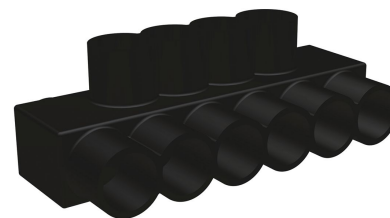

Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	4 AWG-600 KCMIL
Conductor - AL Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil • 450 kcmil • 477 kcmil • 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil
Conductor - AL Str Size Range	4 AWG - 600 kcmil
Conductor Type	• AL C Str-Size • CU C Str-Size

Conductor - Copper Str Size Range 4 AWG - 600 kcmil

Conductor - Copper Str Size

- 4 AWG
- 3 AWG
- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil
- 300 kcmil
- 350 kcmil
- 400 kcmil
- 450 kcmil
- 500 kcmil
- 550 kcmil
- 600 kcmil

Configuration

Physical Attribute - Number of Screws	4
Number Of Ports	4
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	69.9 mm
Length	7.8 in
Dimension - Height inch	2.75 in
Dimension - Height fraction	2.75 in
Package Weight	0.000 lb.
Dimension - Width mm	76 mm
Dimension - Width inch	3.00 in
Package Length	0.000 in
Package Width	0.000 in
Height	2.75 in
Width	3 in
Dimensions	7.8 in x 3 in x 2.75 in

General

Physical Attribute - Screw Type	Allen
---------------------------------	-------

Plated	N
Insulation Type	Plastisol
Material - Hardware	Aluminum
UPC	781810307700
Insulation	Y
Hex Key	3/8
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810307700
UPC 14 Digit GTIN	00781810307700

Minimum Pack Quantity	1
Pallet Quantity	640
Carton Quantity	20

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)

[Catalog \[English\]](#)

Logistics



A Hubbell brand