



1PLO3502, UV Black, Offset Entry, 2-Port,
10 AWG-350 kcmil

By Burndy
Catalog # [1PLO3502](#)

UV Rated Covering, Oxide inhibitor pre-installed, Opposite Side,
2-Port Tap, #10 AWG-350 kcmil

Features


- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UL Listed Direct Burial	No
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor Size	10 AWG-350 KCMIL
Conductor - AL Str Size	• 8 AWG • 6 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil
Conductor - AL Str Size Range	8 AWG - 350 kcmil
Conductor Type	• AL C Str-Size • CU C Str-Size
Conductor - Copper Str Size Range	10 AWG - 350 kcmil
Conductor - Copper Str Size	• #10 • 9 AWG • 8 AWG • 7 AWG

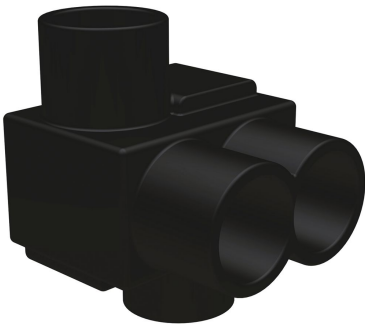

- 6 AWG
- 5 AWG
- 4 AWG
- 3 AWG
- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil
- 300 kcmil
- 350 kcmil

Configuration

Physical Attribute - Number of Screws	2
Number Of Ports	2
Connector Type	Multi Tap

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	63.5 mm
Length	2.22 in
Dimension - Height inch	2.50 in
Dimension - Height fraction	2.5 in
Package Weight	0.000 lb.
Dimension - Width mm	76 mm
Dimension - Width inch	3.00 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	56 mm
Height	2.5 in
Width	3 in
Dimension - Screw Size inch	5/8
Dimension - Length Overall inch	2.22 in
Dimensions	2.22 in x 3 in x 2.5 in

Force Related

Installation Torque	275 LBS/in	UPC 12 Digit	781810453858
Recommended in-lb		UPC 14 Digit GTIN	00781810453858
General		Logistics	
Physical Attribute - Screw Type	Allen	Minimum Pack Quantity	1
Plated	N	Pallet Quantity	1
Insulation Type	Plastisol	Carton Quantity	1
Trade Name	UNITAP™	Operational	
Material - Hardware	Aluminum	Temperature Rating	194
UPC	781810453858	Product Assets	
Insulation	Y	Catalog [English]	
Hex Key	5/16	Catalog [English]	
Material	Aluminum		
Plating Type	Unplated		



A Hubbell brand