



BA14EZ2, Vinyl Flanged Fork Terminal For 16 - 14 AWG

By Burndy
Catalog # [BA14EZ2](#)

Vinyl Flanged Fork Terminal For 16 - 14 AWG

Features

- Locking Fork Tongue design
- Allows for fast installation, screw only has to be loosened for termination
- Internal configuration of the fork prevents the terminal from coming off the screw without applying a pulling force
- Locking form is made from copper alloy and permits many installations while maintaining proper spring retention of forks

Specifications


Standards - Industry Standards Met	UL486
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	Yes
UL Listed	Yes

Conductor

Conductor - Copper Solid Size	• 16 AWG • 15 AWG • 14 AWG
Conductor - Copper Solid Size Range	16 AWG-14 AWG
Conductor Size	16 - 14 AWG
Conductor - Copper Str Size	• 16 AWG • 14 AWG
Conductor - Copper Str Size Range	16 AWG - 14 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size

Configuration

Physical Attribute - Number of Holes	1
Connector Type	Flanged Fork Terminal

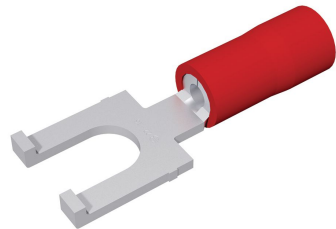

Dimensions

Dimension - Z inch	0.23 in
Dimension - Pad Width inch	0.17 in
Length	0.78 in
Dimension - Hole Size fraction	1/11
Dimension - Bolt Size fraction	#2
Dimension - Hole Size inch	0.09 in
Dimension - Stud Size inch	#2
Dimension - Length Overall inch	0.78 in
Width	0.18 in
Height	0.18 in
Dimensions	0.78 in x 0.18 in x 0.18 in

General

Insulation Type	Vinyl
Color Code	Blue
Physical Attribute - Tongue Type	Fork
Trade Name	VINYLUG™
Plated	Y
Feature - Barrel Style	Shrouded
Insulation	Y
Type	Flange Fork
UPC 14 Digit GTIN	00781810243640
Material	Copper
Plating Type	Tin - Electro Plated
UPC	781810243640

Logistics

Minimum Pack Quantity	10000
Carton Quantity	1000
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)