




BA16EZ6, Vinyl Flanged Fork Terminal For 22 - 16 AWG

By Burndy
Catalog # [BA16EZ6](#)

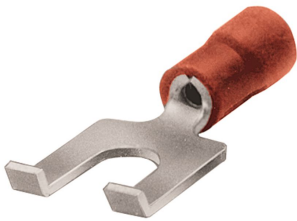

Vinyl Flanged Fork Terminal For 22 - 16 AWG

Features

- Flanged Fork Tongue design allows for fast installation as screw only has to be loosened for termination
- Flanges on the end of the fork terminal aid in preventing a slightly loose terminal from becoming fully disconnected from the screw
- Flanges make re-securing a loose terminal easier

Application

For Fast Installation And Security

Specifications

Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Industry Standard(s)	UL467
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - Industry Standards Met	UL486
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	Yes
UL Listed	Yes

Conductor

Conductor - Copper Solid Size Range	• 20 AWG -22 AWG • 16 AWG -18 AWG
Conductor Size	22 - 16 AWG
Conductor - Copper Str Size Range	• 20 AWG - 22 AWG • 16 AWG - 18 AWG
Conductor Type	CU C Str-Size

Configuration

Physical Attribute - Number of Holes	1
Connector Type	Flanged Fork Terminal

Dimensions

Dimension - Pad Width inch	0.28 in
Dimension - Hole Size fraction	3/20
Dimension - Hole Size inch	0.15 in
Dimension - Stud Size inch	#6
Width	0.28 in
Dimension - Z inch	0.23 in
Length	0.83 in
Dimension - Bolt Size fraction	#6
Dimension - Length Overall inch	0.83 in
Height	0.28 in
Dimensions	0.83 in x 0.28 in x 0.28 in

General

Insulation Type	Vinyl
Trade Name	VINYLUG™
Insulation	Y
Sub Brand	VINYLUG
Physical Attribute - Tongue Type	Flanged Fork
Plated	Y
Feature - Barrel Style	Shrouded
Type	Flange Fork
UPC 12 Digit	781810026786
UPC 14 Digit GTIN	00781810026786
Material	Copper
Plating Type	Tin - Electro Plated
UPC	781810026786

Logistics

Minimum Pack Quantity	1000
Carton Quantity	1000
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)