




BDBCOVER1, Power Distribution Block Cover

By Burndy
Catalog # [BDBCOVER1](#)

Power Distribution Block Cover, 5.36 IN L

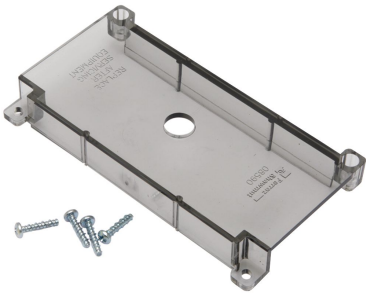

Features

- 600V, AL Rated - meets industry standard requirements
- CSA Approved
- Temperature rating at 194 F and 380A amperage rating
- Tin-plated for corrosion resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
UL Listed	No
Certification - CSA Approved	No

Conductor

Number Of Poles	2
Conductor Type	• AL C Str-Run • CU C Str-Run • AL C Str-Tap • CU C Str-Tap

Current

Rating - Minimum Voltage	600
--------------------------	-----

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Length	5.36 in
Package Weight	0.000 lb.

Dimension - Width mm	74 mm
Dimension - Width inch	2.90 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	136 mm
Height	2.9 in
Width	0.51 in
Dimension - Hole Size mm	7 mm
Dimension - Hole Size inch	0.28 in
Dimension - Length Overall inch	5.36 in
Dimensions	5.36 in x 0.51 in x 2.9 in

General

Plated	N
Trade Name	VERSIPOLE™
UPC	781810115336
Material	Polycarbonate
Plating Type	Unplated
UPC 12 Digit	781810115336
UPC 14 Digit GTIN	00781810115336

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	100

Operational

Temperature Rating	194° F
--------------------	--------

Product Assets

[Catalog \[English\]](#)