




Image represents single pole

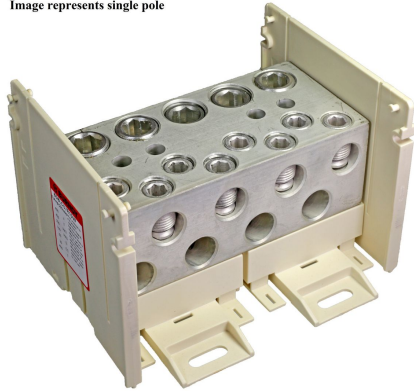

BDBLCS7R1DW, Large Flex Rated Power Distribution Block

By Burndy
Catalog # [BDBLCS7R1DW](#)

Double Wide Power Distribution Block, 1 Pole, Run: #4 AWG - 500 (B,C,H,I,K, 535 DLO), Tap: #6-4/0 AWG (B,C,H,I,K, DLO)

Features

- AL9CU dual rated for use with copper and aluminum conductors
- Range taking designs to accommodate wire sizes up to 535 DLO and can support 1 or 2 run conductors and up to 12 taps for secondary circuits
- Allow for panel mounting, medium and large sizes also allow for DIN rail mounting
- Finger-Safe style are provided with translucent polycarbonate top covers and end plates permitting easy visual inspection, provide IEC 605219 IP-20 Rating
- Base and side barriers of glass-reinforced nylon 6/6 for extra durability and excellent insulating properties
- UL94 flammability rating of VO
- Double-Wide Series boxes include covers

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

UPC	621945481633
-----	--------------

Logistics

Pallet Quantity	216
Carton Quantity	3

Product Assets

[Catalog \[English\]](#)